

Protective covers - HC-STA-B06-DC-PL - 1421100


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Protective covers, Design: B6, Degree of protection: IP20

RoHS

Key Commercial Data

Packing unit	1 STK
Minimum order quantity	5 STK
GTIN	 4 055626 251806
GTIN	4055626251806
Weight per Piece (excluding packing)	20.000 g
Custom tariff number	85389099
Country of origin	China

Technical data

Dimensions

Height	22.1 mm
Width	46.4 mm
Length	62.5 mm

Ambient conditions

Degree of protection of housing (IP)	IP20
Ambient temperature (operation)	0 °C ... 20 °C

General

Size	B6
Color	transparent

Protective covers - HC-STA-B06-DC-PL - 1421100


Technical data

General

Locking type	Clip locking
Material, protective cover	PA

Drawings

Dimensional drawing

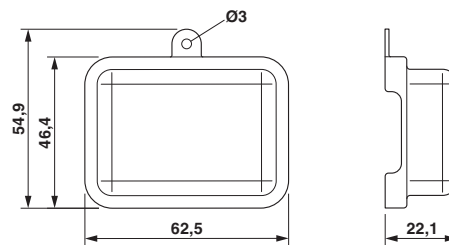

Classifications

eCl@ss

eCl@ss 5.1	27260703
eCl@ss 8.0	27440208
eCl@ss 9.0	27440208

ETIM

ETIM 5.0	EC002314
ETIM 6.0	EC002314

UNSPSC

UNSPSC 13.2	39121421
-------------	----------