

Cable reel - SAC-5P-22AWG-OE-OE-535-100,0SH - 1422038


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



By the meter, Cable reel, shielded, PVC, black, 5-wire, Color, single wire: Brown, blue, black, white, gray, Cable length: 100 m



Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 325033
GTIN	4055626325033
Custom tariff number	85444290
Country of origin	United States

Technical data

Dimensions

Length of cable	100 m
-----------------	-------

General

Number of positions	5
---------------------	---

Cable

Cable type	Black PVC 105°C
Cable type (abbreviation)	535
UL AWM style	2517 (105 °C / 300 V)
AWG signal line	22
Core diameter including insulation	1.27 mm ±0.03 mm
Wire colors	Brown, blue, black, white, gray
Overall twist	5 wires around filler to the core

Cable reel - SAC-5P-22AWG-OE-OE-535-100,0SH - 1422038


Technical data

Cable

Shielding	Tinned copper braided shield
Optical shield covering	85 %
External sheath, color	black
External cable diameter D	5.9 mm \pm 0.2 mm
Minimum bending radius, flexible installation	12 x D
Cable weight	57 kg/km
Outer sheath, material	PVC
Material, filler	PP
Material conductor insulation	PVC
Conductor material	Tin-plated Cu litz wires
Nominal voltage, cable	300 V
Special properties	UL standards PLTC and ITC
Flame resistance	FT4
Other resistance	UV resistant
Ambient temperature (operation)	-30 °C ... 105 °C (cable, fixed installation)

Drawings

Cable cross section

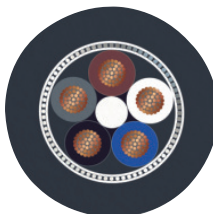

Black PVC 105°C [535]