

Housing - HC-STA-D15-SLWSC-2SSM20-EL-AL - 1424369

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Box mounting bases D15, With single locking latch, Material: Die-cast aluminum, salt water resistant, Protective cover material: PA, Cable outlets: 2, lateral, Height: 52 mm, Cable gland: none, Gland: no, 2x M20, Protective cover: Yes, Standard



Key Commercial Data

| | |
|--------------|---------------|
| Packing unit | 1 |
| GTIN | |
| GTIN | 4055626371108 |

Technical data

Dimensions

| | |
|--------|-------|
| Height | 52 mm |
| Width | 51 mm |
| Length | 80 mm |

Ambient conditions

| | |
|--|-------------------|
| Degree of protection of housing (IP) | IP66 |
| | IP67 |
| Degree of protection of housing (NEMA) | 4 (UL 50e) |
| | 4X (UL 50e) |
| | 12 (UL 50e) |
| Ambient temperature (operation) | -40 °C ... 125 °C |

General

| | |
|--------------|--------------------|
| Size | D15 |
| Housing type | Box mounting bases |

Housing - HC-STA-D15-SLWSC-2SSM20-EL-AL - 1424369


Technical data

General

| | |
|------------------------------|---|
| Color | silver |
| Locking type | With single locking latch |
| No. of cable outlets | 2 |
| Cable exit | lateral |
| Screw connection | none |
| Type of the screw connection | 2x M20 |
| Protective cover | Yes |
| Housing material | Die-cast aluminum, salt water resistant |
| Material lock | PA |
| Material, protective cover | PA |

Drawings

Dimensional drawing

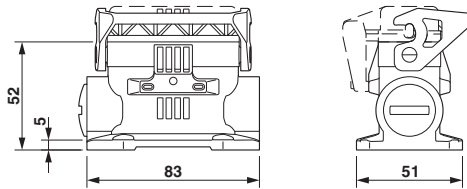

Dimensional drawing