

Housing - HC-STA-D25-BWS-EL-AL - 1424391

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Panel mounting base D25, With single locking latch, Material: Die-cast aluminum, salt water resistant, Height: 26 mm, Cable gland: none, Gland: no, Standard



Key Commercial Data

Packing unit	1
GTIN	
GTIN	4055626371313

Technical data

Dimensions

Height	26 mm
Width	39 mm
Length	97 mm
Length of the assembly cutout	74 mm
Width of the assembly cutout	24 mm

Ambient conditions

Degree of protection of housing (IP)	IP66
	IP67
Degree of protection of housing (NEMA)	4 (UL 50e)
	4X (UL 50e)
	12 (UL 50e)
Ambient temperature (operation)	-40 °C ... 125 °C

General

Housing - HC-STA-D25-BWS-EL-AL - 1424391


Technical data

General

Note	For contact inserts HC-D25, A16
Size	D25
Housing type	Panel mounting base
Color	silver
Locking type	With single locking latch
Screw connection	none
Housing material	Die-cast aluminum, salt water resistant
Material lock	PA

Drawings

Dimensional drawing

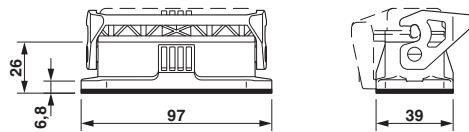

Dimensional drawing