

Housing - HC-STA-D50-HHFD-1STP29-EL-AL - 1424407


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Sleeve housing D50, for double locking latch, Material: Die-cast aluminum, salt water resistant, Cable outlets: 1, lateral, Height: 80 mm, Cable gland: none, Gland: no, 1x Pg29, Standard



Key Commercial Data

Packing unit	1
GTIN	 4 055626 371474
GTIN	4055626371474

Technical data

Dimensions

Height	80 mm
Width	56 mm
Length	82 mm

Ambient conditions

Degree of protection of housing (IP)	IP66
	IP67
Degree of protection of housing (NEMA)	4 (UL 50e)
	4X (UL 50e)
	12 (UL 50e)
Ambient temperature (operation)	-40 °C ... 125 °C

General

Size	D50
Housing type	Sleeve housing

Housing - HC-STA-D50-HHFD-1STP29-EL-AL - 1424407


Technical data

General

Color	silver
Locking type	for double locking latch
No. of cable outlets	1
Cable exit	lateral
Screw connection	none
Type of the screw connection	1x Pg29
Housing material	Die-cast aluminum, salt water resistant
Housing surface material	Uncoated

Drawings

Dimensional drawing

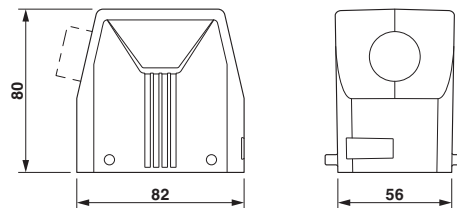

Dimensional drawing

Classifications

eCl@ss

eCl@ss 5.1	27143424
eCl@ss 6.0	27261203
eCl@ss 7.0	27440202
eCl@ss 8.0	27440202
eCl@ss 9.0	27440202

ETIM

ETIM 5.0	EC000437
----------	----------