

Cable gland - G-INS-PG36-M68N-PNES-LG - 1424492


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Cable gland, Cable gland material: PA, External cable diameter 22 mm ... 32 mm, Shielding: No, Connecting thread: Pg36, Color: lightgrey RAL 7035



Key Commercial Data

Packing unit	1
GTIN	 4 055626 373225
GTIN	4055626373225
Custom tariff number	39269097

Technical data

Dimensions

Length	65 mm
Wrench size, union nut	53 mm
Wrench size, support	53 mm
Hexagon angular dimension	60 mm
Length of the connecting thread	13 mm
Feed-through hole diameter	47.1 mm ... 47.4 mm
External cable diameter	22 mm ... 32 mm
	22 mm ... 32 mm (for UL 514 B)

Ambient conditions

Degree of protection	IP68 (5 bar / 0.5 h)
Ambient temperature (operation)	-20 °C ... 100 °C (static)

General

Cable gland - G-INS-PG36-M68N-PNES-LG - 1424492

Technical data

General


No. of conductors	1
Cable gland material	PA
Cable seal material	Neoprene
Shielded	No
Thread type on connection side	Pg36
Torque	11 Nm (Union nut)
	11 Nm (Support)
	20 Nm (for UL514 B: union nut / support)
Flammability rating according to UL 94	V2
	V2 (Housing)
Color	lightgrey RAL 7035
Assembly instructions	1) Mount screw connection support in the housing using the correct torque 2) Insert cable 3) Tighten union nut using the correct torque
Manufacturer	BIMED
Manufacturer Designation	BS-18

Standards and Regulations

Flammability rating according to UL 94	V2
--	----

Drawings

Dimensional drawing

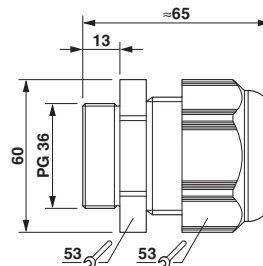

Dimensional drawing

Classifications

eCl@ss

eCl@ss 5.1	27149109
eCl@ss 6.0	27149109
eCl@ss 7.0	27149109

Cable gland - G-INS-PG36-M68N-PNES-LG - 1424492

Classifications

eCl@ss

eCl@ss 8.0	27149109
eCl@ss 9.0	27144432

ETIM

ETIM 5.0	EC000441
----------	----------

Approvals

Approvals

Approvals

UL Listed / cUL Listed / EAC / cULus Listed

Ex Approvals

Approval details

UL Listed		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	E199260
-----------	--	---	---------

cUL Listed		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	E199260
------------	--	---	---------

EAC		EAC-Zulassung
-----	--	---------------

cULus Listed		
--------------	--	--

Accessories

Accessories

Flat nut

Cable gland - G-INS-PG36-M68N-PNES-LG - 1424492

Accessories

Nut - A-INL-PG36-P-GY - 1411228



Nut, PA, for threads Pg36, Color: silver-gray RAL 7001

Sealing plugs

Closing cap - SEALING PLUG 28X30 RD - 1421864



Closing cap, PA, Color: red