

Screw plug - A-INSP-M32-68N-P-LG - 1424521

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Screw plug, material: PA, connecting thread: M32 x 1.5, color: lightgrey RAL 7035



RoHS

Key Commercial Data

Packing unit	1 pc
Minimum order quantity	10 pc
GTIN	 4 055626 374260
GTIN	4055626374260
Weight per Piece (excluding packing)	8.000 g
Custom tariff number	39269097
Country of origin	Germany

Technical data

Dimensions

Length	12 mm
Connecting thread diameter	32 mm
Hexagon angular dimension	37 mm (Diameter)
Length of the connecting thread	8 mm

Ambient conditions

Degree of protection (IP)	IP68
	IP66
Ambient temperature (operation)	-40 °C ... 100 °C

General

Screw plug - A-INSP-M32-68N-P-LG - 1424521

Technical data

General

Material	PA
Sealing material	EPDM (O-ring)
Thread type on connection side	M32 x 1.5
Torque	2 Nm
Color	lightgrey RAL 7035
Manufacturer	WISKA
Manufacturer Designation	EVSG-ORD 32

Standards and Regulations

Halogen-free	yes
--------------	-----


Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Screw plug - A-INSP-M32-68N-P-LG - 1424521

Dimensional drawing

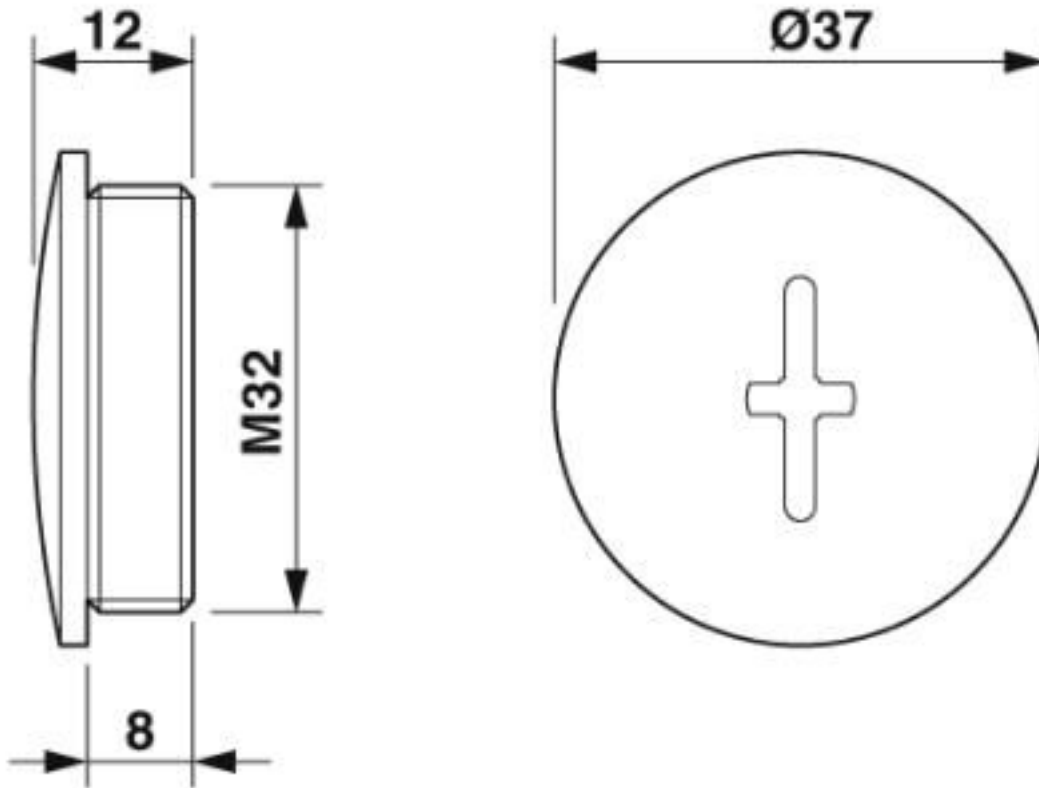

Dimensional drawing

Classifications

eCl@ss

eCl@ss 10.0.1	23111190
eCl@ss 4.0	23111100
eCl@ss 4.1	23111100
eCl@ss 5.0	23111100
eCl@ss 5.1	23111100
eCl@ss 6.0	23111100
eCl@ss 7.0	23111190
eCl@ss 8.0	23111190
eCl@ss 9.0	23111190

ETIM

ETIM 5.0	EC000032
----------	----------

Screw plug - A-INSP-M32-68N-P-LG - 1424521

Classifications

ETIM

ETIM 6.0	EC000032
ETIM 7.0	EC000032

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		EAC-Zulassung
-----	---	---------------

Accessories

Accessories

Flat nut

Counter nut - A-INL-M32-P-LG - 1417662

Counter nut, material: PA 6 GF 30, for threads M32 x 1.5, color: lightgrey RAL 7035

