

## Nut - A-INL-PG21-P-BK - 1424563


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Nut, PA 6 GF 30, Connecting thread: Pg21, Color: jet black RAL 9005



RoHS

### Key Commercial Data

Packing unit	1
GTIN	 4 055626 374673
GTIN	4055626374673
Custom tariff number	39269097

### Technical data

#### Dimensions

Length	7 mm
Connecting thread diameter	28.3 mm
Wrench size, counter nut	36 mm
Hexagon angular dimension	39 mm

#### Ambient conditions

Ambient temperature (operation)	-20 °C ... 100 °C
---------------------------------	-------------------

#### General

Material	PA 6 GF 30
Thread type on connection side	Pg21
Flammability rating according to UL 94	V2
Color	jet black RAL 9005

### Standards and Regulations

# Nut - A-INL-PG21-P-BK - 1424563


## Technical data

### Standards and Regulations

Flammability rating according to UL 94	V2
--	----

## Drawings

Dimensional drawing

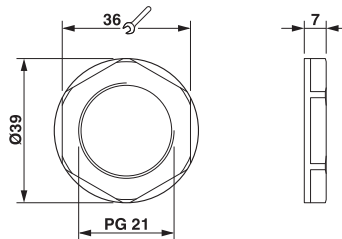

## Classifications

### eCl@ss

eCl@ss 5.1	27149109
eCl@ss 6.0	27149109
eCl@ss 8.0	27069219
eCl@ss 9.0	27144424

### ETIM

ETIM 5.0	EC000129
----------	----------

## Approvals

### Approvals

---

Approvals

EAC

---

Ex Approvals

---

### Approval details

## Nut - A-INL-PG21-P-BK - 1424563

### Approvals

EAC



EAC-Zulassung