

## Sealing cap - PROT-M 8 FS-PA-CHAIN - 1430857

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

M8 sealing cap made of plastic with fixing band for sensor cables, for M8 plugs



RoHS

### Key Commercial Data

Packing unit	1 STK
Minimum order quantity	10 STK
GTIN	 4 046356 332866
GTIN	4046356332866
Weight per Piece (excluding packing)	2.800 g
Custom tariff number	39269097
Country of origin	Germany

### Technical data

#### Ambient conditions

Ambient temperature (operation)	-25 °C ... 85 °C
Degree of protection	IP65
	IP67

#### Material

Flammability rating according to UL 94	V0
Material	PA 66 GF
Sealing material	NBR
Additional material specifications	PUR (Holding band)

### Standards and Regulations

# Sealing cap - PROT-M 8 FS-PA-CHAIN - 1430857

## Technical data

### Standards and Regulations


Flammability rating according to UL 94	V0
--	----

### Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

## Drawings

Dimensional drawing

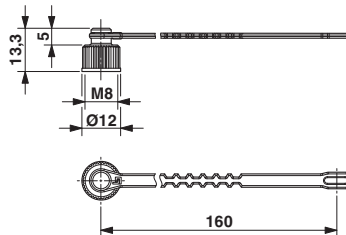

Dimensional drawing

## Classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27149110
eCl@ss 5.1	27149110
eCl@ss 6.0	27149112
eCl@ss 7.0	27149112
eCl@ss 8.0	23111190
eCl@ss 9.0	23111190

ETIM

ETIM 3.0	EC002040
ETIM 4.0	EC002040
ETIM 5.0	EC002040
ETIM 6.0	EC000032

# Sealing cap - PROT-M 8 FS-PA-CHAIN - 1430857

## Classifications

### UNSPSC

UNSPSC 6.01	31251501
UNSPSC 7.0901	31251501
UNSPSC 11	31251501
UNSPSC 12.01	31251501
UNSPSC 13.2	31251501

## Approvals

### Approvals

---

#### Approvals

EAC

---

#### Ex Approvals

---

### Approval details

EAC		EAC-Zulassung
-----	---	---------------

---