

## Housing - HC-B 24-TFQ-H-M1PG29G - 1460232


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON B24 sleeve housing, for double locking latch, height: 76 mm, with 1 x Pg29 screw connection, straight cable outlet



### Key Commercial Data

Packing unit	1 STK
GTIN	 4 046356 794305
GTIN	4046356794305
Weight per Piece (excluding packing)	314.000 g
Custom tariff number	85389099
Country of origin	Germany

### Technical data

#### Ambient conditions

Degree of protection of housing (IP)	IP65
Ambient temperature (operation)	-40 °C ... 125 °C

#### General

Note	For contact inserts HC-B24, BB46, BBB64, D64, DD108, M
Size	B24
Housing type	Sleeve housing
Locking type	for double locking latch
No. of cable outlets	1
Cable exit	straight
Screw connection	with
Type of the screw connection	1x Pg29

# Housing - HC-B 24-TFQ-H-M1PG29G - 1460232

## Technical data

### General


Housing material	Aluminum die-cast
Housing surface material	Powder-coated, gray
Cable gland material	Brass
Cable seal material	NBR

### Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

## Drawings

Dimensional drawing

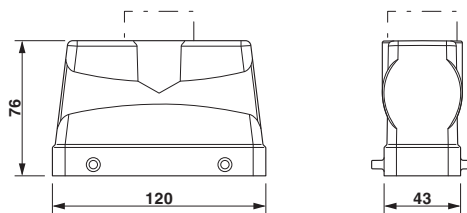

Dimensional drawing

## Approvals

Approvals

Approvals

EAC

Ex Approvals

## Approval details

EAC 7500651.22.01.00246
-------------------------