


Sensor/actuator cable - SAC-4P-M12MR/ 1,5-PUR/M12FR TP - 1505193

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Sensor/actuator cable, 4-position, PUR/PVC, green RAL 6017, Plug angled M12, A-coded, on Socket angled M12, A-coded, cable length: 1.5 m

Key Commercial Data

Packing unit	1 STK
GTIN	 4 017918 902377
GTIN	4017918902377

Technical data

Dimensions

Length of cable	1.5 m
-----------------	-------

Ambient conditions

Degree of protection	IP65
	IP67
	IP68

General

Rated current at 40°C	4 A
Rated voltage	250 V AC
	250 V DC
Number of positions	4
Insulation resistance	≥ 100 MΩ
Coding	A - standard
Status display	No
Overvoltage category	II
Degree of pollution	3
Insertion/withdrawal cycles	≥ 100

Material

Flammability rating according to UL 94	HB
Contact material	CuSn
Contact surface material	Ni/Au
Contact carrier material	TPU GF

Sensor/actuator cable - SAC-4P-M12MR/ 1,5-PUR/M12FR TP - 1505193

Technical data

Material

Material of grip body	TPU, hardly inflammable, self-extinguishing
Material, knurls	Zinc die-cast, nickel-plated
Sealing material	NBR

Standards and Regulations


Flammability rating according to UL 94	HB
--	----

Cable

Cable type	PUR/PVC green
Cable type (abbreviation)	350
Conductor cross section	0.5 mm ²
AWG signal line	20
Conductor structure signal line	28x 0.15 mm
Thickness, insulation	Core insulation
	approx. 1 mm (Inner sheath)
	approx. 0.7 mm (Outer cable sheath)
Wire colors	Brown-white, green-yellow
External sheath, color	green RAL 6017
External cable diameter	7.80 mm
Smallest bending radius, movable installation	78 mm
Number of bending cycles	2000000
Bending radius	78 mm
Traversing path	5 m
Traversing rate	3 m/s
Outer sheath, material	PUR
Material, inner sheath	PVC
Material conductor insulation	PVC
Conductor material	Bare Cu litz wires
Nominal voltage, cable	300 V
Test voltage, cable	1500 V
Ambient temperature (operation)	-25 °C ... 80 °C (cable, fixed installation)
	-5 °C ... 80 °C (cable, flexible installation)


Drawings

Schematic diagram

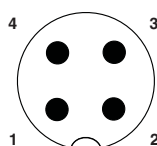

Pin assignment M12 plug, 4-pos., A-coded, view plug side


Schematic diagram

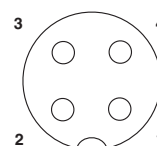

Pin assignment M12 socket, 4-pos., A-coded, view female side


Sensor/actuator cable - SAC-4P-M12MR/ 1,5-PUR/M12FR TP - 1505193

Dimensional drawing

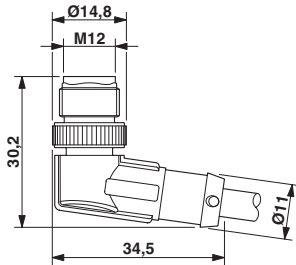

M12 x 1 male plug, angled

Dimensional drawing

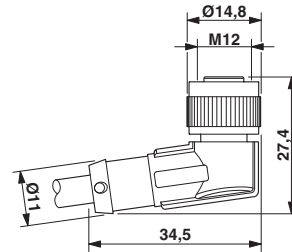

M12 x 1 socket, angled

Circuit diagram

