

T distributor - SAC-3P-M12T/2XM12 B PE - 1519723

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



T distributor, 3-position, Plug straight M12, A-coded, on Socket straight M12, A-coded, PIN 2+4 bridged and Socket straight M12, A-coded, PIN 2+4 bridged

The illustration shows the 5-pos. version



Key Commercial Data

Packing unit	1 pc
Weight per Piece (excluding packing)	26.2 g
Custom tariff number	85366990
Country of origin	Germany

Technical data

Ambient conditions

Ambient temperature (operation)	-25 °C ... 90 °C (Plug / socket)
Degree of protection	IP65
	IP67

General

Rated current at 40°C	4 A
Rated voltage	60 V
Number of positions	3
Insulation resistance	≥ 100 MΩ
Coding	A - standard
Standards/regulations	M12 connector IEC 61076-2-101
Status display	No
Overvoltage category	II
Degree of pollution	3
Insertion/withdrawal cycles	≥ 100

T distributor - SAC-3P-M12T/2XM12 B PE - 1519723

Technical data

General

Torque	0.4 Nm (M12 connector)
--------	------------------------

Material

Flammability rating according to UL 94	HB
Contact material	CuZn
Contact surface material	Ni/Au
Contact carrier material	TPU GF
Material of grip body	TPU, hardly inflammable, self-extinguishing
Material, knurls	Zinc die-cast, nickel-plated
Sealing material	NBR

Standards and Regulations

Standard designation	M12 connector
Standards/regulations	IEC 61076-2-101
Flammability rating according to UL 94	HB

Classifications

eCl@ss

eCl@ss 4.0	27060306
eCl@ss 4.1	27060306
eCl@ss 5.0	27061801
eCl@ss 5.1	27061801
eCl@ss 6.0	27061801
eCl@ss 7.0	27061801
eCl@ss 8.0	27440104
eCl@ss 9.0	27440102

ETIM

ETIM 2.0	EC000830
ETIM 3.0	EC001855
ETIM 4.0	EC001855
ETIM 5.0	EC002062

UNSPSC

UNSPSC 6.01	31251501
UNSPSC 7.0901	31251501
UNSPSC 11	31251501
UNSPSC 12.01	31251501

T distributor - SAC-3P-M12T/2XM12 B PE - 1519723

Classifications

UNSPSC

UNSPSC 13.2	31251501
-------------	----------

Approvals

Approvals

Approvals

EAC / UL Listed

Ex Approvals

Approvals submitted


Approval details

EAC

UL Listed	
Nominal current I_N	4 A
Nominal voltage U_N	30 V


Drawings

Schematic diagram

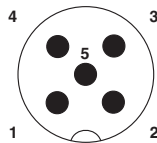

Pin assignment M12 male connector, 5-pos., A-coded, male side


Schematic diagram

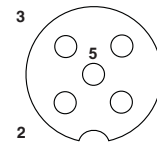


Pin assignment M12 socket, 5-pos., A-coded, socket side view

T distributor - SAC-3P-M12T/2XM12 B PE - 1519723

Dimensional drawing

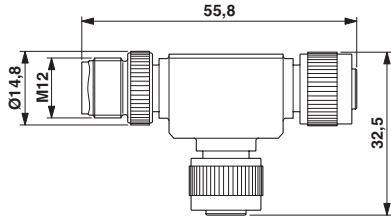


Circuit diagram

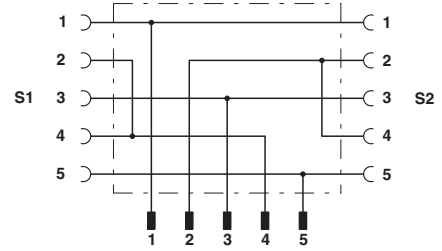

M12 T-distributor

Contact assignment of the M12 T distributor

Schematic diagram

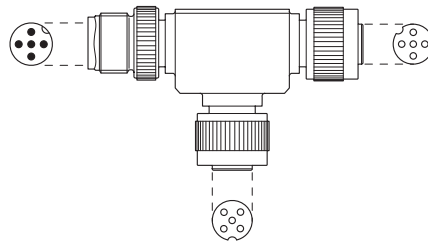

Layout of connector pin assignments