

Contact insert - HC-A04-I-PT-M - 1585278


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Contact insert, Size: D7, Number of positions: 4+PE, Pin, Push-in connection, 230 V, 10 A, 0.14 mm² ... 1.5 mm²



Key Commercial Data

Packing unit	1
GTIN	 4 046356 285001
GTIN	4046356285001
Custom tariff number	85369010

Technical data

General

Note	For housing HC-D7
Connection method	Push-in connection
Degree of pollution	3
Overvoltage category	III
Number of positions	4+PE
Insertion/withdrawal cycles	≥ 500
Size	D7
Conductor cross section	0.14 mm ² ... 1.5 mm ² (with ferrule)
Connection cross section AWG	26 ... 16 (with ferrule)
Assembly instructions	Connectors may be operated only when there is no load/voltage.

Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C
---------------------------------	-------------------

Contact insert - HC-A04-I-PT-M - 1585278

Technical data

Material data

Contact surface material	Ag
Contact carrier material	PC
Standards/regulations	PC: Fire protection in rail vehicles - requirement sets R22, R23, and R24 acc. to DIN EN 45545-2 (Risk level HL1 - HL3)

Electrical characteristics

Rated voltage for power contacts	230/400 V
Rated voltage (III/3)	230 V (Conductor-PE)
	400 V (Conductor-Conductor)
Rated surge voltage	4 kV
Rated current	10 A

Standards and Regulations

Flammability rating according to UL 94	V0
--	----


Drawings

Schematic diagram



Connector pin assignment connection side: Left pin; right socket

Dimensional drawing

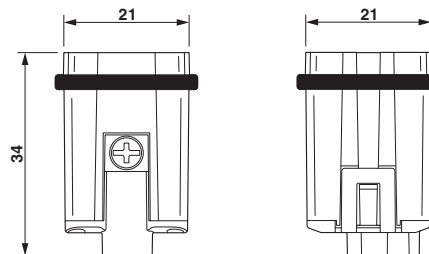

Male insert

Classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	27440205
eCl@ss 9.0	27440205

Contact insert - HC-A04-I-PT-M - 1585278

Classifications

ETIM

ETIM 4.0	EC000438
ETIM 5.0	EC000438

UNSPSC

UNSPSC 6.01	30211923
UNSPSC 7.0901	39121522
UNSPSC 11	39121522
UNSPSC 12.01	39121522
UNSPSC 13.2	39121522

Accessories

Accessories

Coding element

Coding profile - HC-MOD-K-CP - 1408562



Coding profile for HC-MOD-K... housing

Seal

Profile gasket - HC-D07-SP-RBK - 1419622



Profile gasket, Design: D7, for pin inserts