

Panel mounting base - RC-00000004200 - 1592589

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Panel mounting base, straight, Screw locking, M23, Radial O-ring, 4x M2.5, shielded: yes, Panel thickness min.: 2.7 mm, Panel thickness max.: 3.5 mm



Key Commercial Data

Packing unit	1 STK
Weight per Piece (excluding packing)	27.910 g
Custom tariff number	85389099
Country of origin	Germany

Technical data

General

Note	Order information: Order contact inserts separately
Type of locking	Screw locking
Pg housing screw connection	none
Mounting type	4x M2.5

Ambient conditions

Ambient temperature	-20 °C ... 125 °C
Degree of protection	IP67

Material

Housing material	Turned parts: copper zinc alloy (CuZn), die-cast parts: zinc (GD-Zn)
Gasket and O-ring material	FPM

Specifications according to DIN EN 61984:2001

Installation height max.	2000 m
--------------------------	--------

Environmental Product Compliance

Panel mounting base - RC-00000004200 - 1592589


Technical data

Environmental Product Compliance


China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Drawings


Diagram

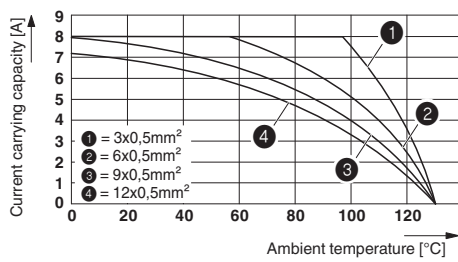

Diagram

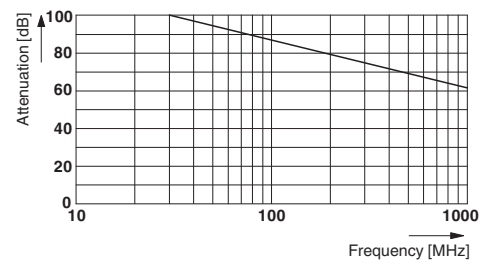

Dimensional drawing

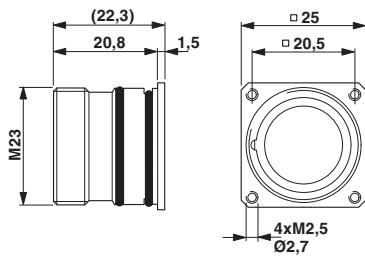

Dimensional drawing

