


Screw plug - HC-M-BS-M25 - 1645859

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Filler plug, metal, size: M25



Key Commercial Data

Packing unit	1 pc
Minimum order quantity	10 pc
GTIN	 4 017918 951108
GTIN	4017918951108
Weight per Piece (excluding packing)	25.050 g
Custom tariff number	74153300
Country of origin	Germany

Technical data

Dimensions

Length	10 mm
Length without connecting thread	3.5 mm
Connecting thread diameter	25 mm
Wrench size, union nut	28 mm
Hexagon angular dimension	31.5 mm
Length of the connecting thread	6.5 mm

Ambient conditions

Degree of protection (IP)	IP68
Ambient temperature (operation)	-20 °C ... 80 °C

Screw plug - HC-M-BS-M25 - 1645859

Technical data

General

Material	Brass, nickel-plated
O-ring material	NBR
Thread type connection side	M25 x 1.5
Thread type on connection side	M25
Torque	5 Nm
Color	silver

Standards and Regulations

Halogen-free	no
--------------	----


Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Drawings

Screw plug - HC-M-BS-M25 - 1645859

Dimensional drawing

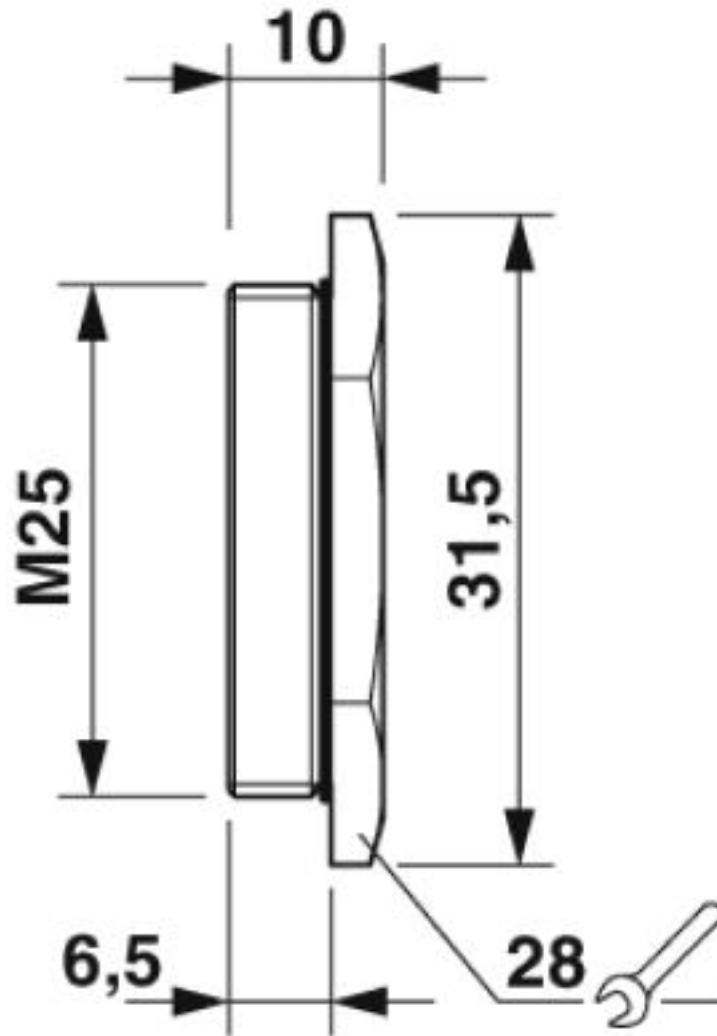

Dimensional drawing

Classifications

eCl@ss

eCl@ss 4.0	27141200
eCl@ss 4.1	27141200
eCl@ss 5.0	27149100
eCl@ss 5.1	27149100
eCl@ss 6.0	27149100

Screw plug - HC-M-BS-M25 - 1645859

Classifications

eCl@ss

eCl@ss 7.0	27149110
eCl@ss 8.0	27149110
eCl@ss 9.0	27144433

ETIM

ETIM 2.0	EC000441
ETIM 3.0	EC000441
ETIM 4.0	EC000032
ETIM 5.0	EC000723
ETIM 6.0	EC000451
ETIM 7.0	EC000451

UNSPSC

UNSPSC 6.01	30211808
UNSPSC 7.0901	39121408
UNSPSC 11	39121408
UNSPSC 12.01	39121408
UNSPSC 13.2	31161501