

Protective covers - HC-B 32-SD-FQU/FS - 1646120

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON protective cover, type B32, for supporting base element with double locking latch, with retaining cord, IP54, PA



Key Commercial Data

Packing unit	1 pc
GTIN	 4 017918 927301
Weight per Piece (excluding packing)	37.11 g
Custom tariff number	39269097
Country of origin	Germany

Technical data

Dimensions

Diameter of retaining cord eyelet	30 mm
-----------------------------------	-------

Ambient conditions

Degree of protection	IP54
Ambient temperature (operation)	-20 °C ... 100 °C

General

Type	B32
	For supporting base element with double locking latch
Flammability rating according to UL 94	HB
Seal present	no
Connection	Plastic protective cover for short-term protection

Standards and Regulations

Protective covers - HC-B 32-SD-FQU/FS - 1646120

Technical data

Standards and Regulations

Flammability rating according to UL 94	HB
--	----

Classifications

eCl@ss

eCl@ss 4.0	27141210
eCl@ss 4.1	27141210
eCl@ss 5.0	27149110
eCl@ss 5.1	27149110
eCl@ss 6.0	27261210
eCl@ss 7.0	27440208
eCl@ss 8.0	27440208
eCl@ss 9.0	27440208

ETIM

ETIM 2.0	EC000241
ETIM 3.0	EC002040
ETIM 4.0	EC002314
ETIM 5.0	EC002314

UNSPSC

UNSPSC 6.01	30212113
UNSPSC 7.0901	39121712
UNSPSC 11	39121712
UNSPSC 12.01	39121712
UNSPSC 13.2	39121712

Approvals

Approvals

Approvals

EAC

Ex Approvals

Protective covers - HC-B 32-SD-FQU/FS - 1646120

Approvals


Approvals submitted

Approval details

EAC

Drawings

Dimensional drawing

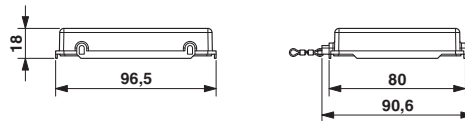

Protective cover, B32