

Housing - HC-D 7-AML-24/GR/PA-A - 1647747

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Panel mounting base, with single locking latch, height 24 mm, with screw connection, PA reusable material, straight version, with metal strap



Key Commercial Data

Packing unit	1 pc
Minimum order quantity	250 pc
Weight per Piece (excluding packing)	25.61 g
Custom tariff number	85389099
Country of origin	Germany

Technical data

Dimensions

Height	24 mm
Width	38 mm
Length	28 mm
Length of the assembly cutout	21.5 mm
Width of the assembly cutout	21.5 mm

Ambient conditions

Degree of protection of housing (IP)	IP54
	IP65 (with sealing screw)
Ambient temperature (operation)	-40 °C ... 125 °C

General

Note	For contact inserts HC-D7, D8, A3, A4, B5, HS2-D7
Type	D7
Housing type	Panel mounting base, straight
Locking type	With single locking latch

Housing - HC-D 7-AML-24/GR/PA-A - 1647747

Technical data

General

Housing material	Polyamide
Housing surface material	PA, light gray
Seal material	NBR
Material lock	Steel, galvanized

Classifications

eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	27440202
eCl@ss 9.0	27440202

ETIM

ETIM 3.0	EC000437
ETIM 4.0	EC000437
ETIM 5.0	EC000437

UNSPSC

UNSPSC 6.01	31261502
UNSPSC 7.0901	31261502
UNSPSC 11	31261502
UNSPSC 12.01	31261502
UNSPSC 13.2	31261502

Approvals

Approvals

Approvals

EAC / GL

Ex Approvals

Housing - HC-D 7-AML-24/GR/PA-A - 1647747

Approvals

Approvals submitted


Approval details

EAC

GL


Drawings

Dimensional drawing

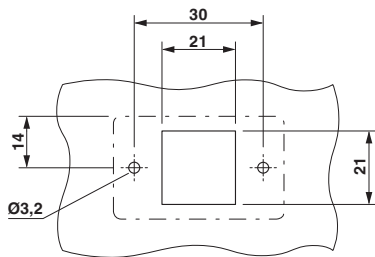

Panel cutout

Dimensional drawing

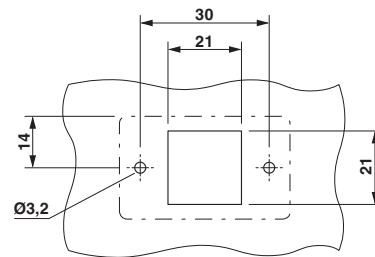

Panel cutout