

# D-SUB panel mounting frames - VS-09-A-GC-BLANK - 1654840

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

D-SUB panel mounting frame, shell size 1, IP67 degree of protection



## Key Commercial Data

|                                      |               |
|--------------------------------------|---------------|
| Packing unit                         | 5 pc          |
| Minimum order quantity               | 5 pc          |
| GTIN                                 |               |
| GTIN                                 | 4046356028820 |
| Weight per Piece (excluding packing) | 9.440 g       |
| Custom tariff number                 | 85369010      |
| Country of origin                    | Germany       |

## Technical data

### Mechanical characteristics

|      |         |
|------|---------|
| Type | D-SUB 9 |
|------|---------|

### Ambient conditions

|                                 |                  |
|---------------------------------|------------------|
| Ambient temperature (operation) | -40 °C ... 80 °C |
|---------------------------------|------------------|

### Material data

|                  |    |
|------------------|----|
| Housing material | PA |
|------------------|----|


### Environmental Product Compliance

|            |   |
|------------|---|
| China RoHS | Environmentally friendly use period: unlimited = EFUP-e |
|            | No hazardous substances above threshold values          |

## Drawings

# D-SUB panel mounting frames - VS-09-A-GC-BLANK - 1654840

Dimensional drawing

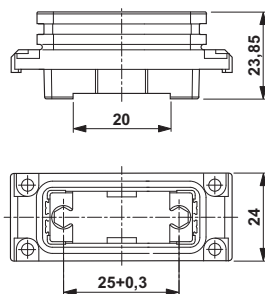

D-SUB panel mounting frame

## Classifications

### eCl@ss

|            |          |
|------------|----------|
| eCl@ss 4.0 | 27140816 |
| eCl@ss 4.1 | 27260701 |
| eCl@ss 5.0 | 27260701 |
| eCl@ss 5.1 | 27260700 |
| eCl@ss 6.0 | 27261200 |
| eCl@ss 7.0 | 27440210 |
| eCl@ss 8.0 | 27440210 |
| eCl@ss 9.0 | 27440210 |

### ETIM

|          |          |
|----------|----------|
| ETIM 2.0 | EC000437 |
| ETIM 3.0 | EC000437 |
| ETIM 4.0 | EC000437 |
| ETIM 5.0 | EC002310 |
| ETIM 6.0 | EC002310 |

### UNSPSC

|               |          |
|---------------|----------|
| UNSPSC 6.01   | 31261501 |
| UNSPSC 7.0901 | 31261501 |
| UNSPSC 11     | 31261501 |
| UNSPSC 12.01  | 31261501 |
| UNSPSC 13.2   | 39121421 |

## Approvals

### Approvals

---

Approvals

EAC

---


## D-SUB panel mounting frames - VS-09-A-GC-BLANK - 1654840

### Approvals

Ex Approvals

---

#### Approval details

|     |   |         |
|-----|---|---------|
| EAC |  | B.01742 |
|-----|---|---------|

### Accessories

#### Accessories

##### Protective cover

D-SUB protective cover - VS-09-SD - 1887086

D-SUB protective cover, material: PA, size of housing: 1, color: gray

