

VS-25-ST-DSUB-HD-CD-B - D-SUB contact support



1655250

<https://www.phoenixcontact.com/de/produkte/1655250>

Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.

D-SUB contact carrier, shell size 3, for 44 signal contacts, type of contact pin, for crimp contacts, straight, fixing with a 3 mm hole, for panel mounting frame and sleeve housing VS-25-...



Your advantages

- Compatible with IP67 sleeve housing and panel-mount frame
- Easy assembly

Commercial Data

Item number	1655250
Packing unit	10 pc
Minimum order quantity	10 pc
Sales Key	D1 - Steckverbinder
Product Key	ABNCAA
Catalog Page	Page 212 (C-2-2013)
GTIN	4046356029193
Weight per Piece (including packing)	13,48 g
Weight per Piece (excluding packing)	7,69 g
Customs tariff number	85366990
Country of origin	DE

Technical Data

Product properties

Type	D-SUB
Product type	Male insert
Number of positions	44
Connection profile	D-SUB 25
Application	high-position
Type	Male
Shielded	no

Insulation characteristics

Overvoltage category	III
Degree of pollution	2

Electrical properties

Rated voltage (III/3)	60 V
Rated surge voltage	1 kV
Rated current	3 A (at 20 °C)
Test voltage	1000 V
Transmission medium	Copper

Material specifications

Flammability rating according to UL 94	V0
Contact material	Copper alloy
Contact carrier material	Glass-fiber reinforced thermoplastics, UL 94 V0
Housing material	Steel, tin-plated

Mechanical properties

Mechanical data

Insertion/withdrawal cycles	≥ 500
-----------------------------	-------

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-55 °C ... 115 °C
---------------------------------	-------------------

Mounting

Mounting type	Hole
Connection method	Crimp connection


VS-25-ST-DSUB-HD-CD-B - D-SUB contact support



1655250

<https://www.phoenixcontact.com/de/produkte/1655250>

Drawings

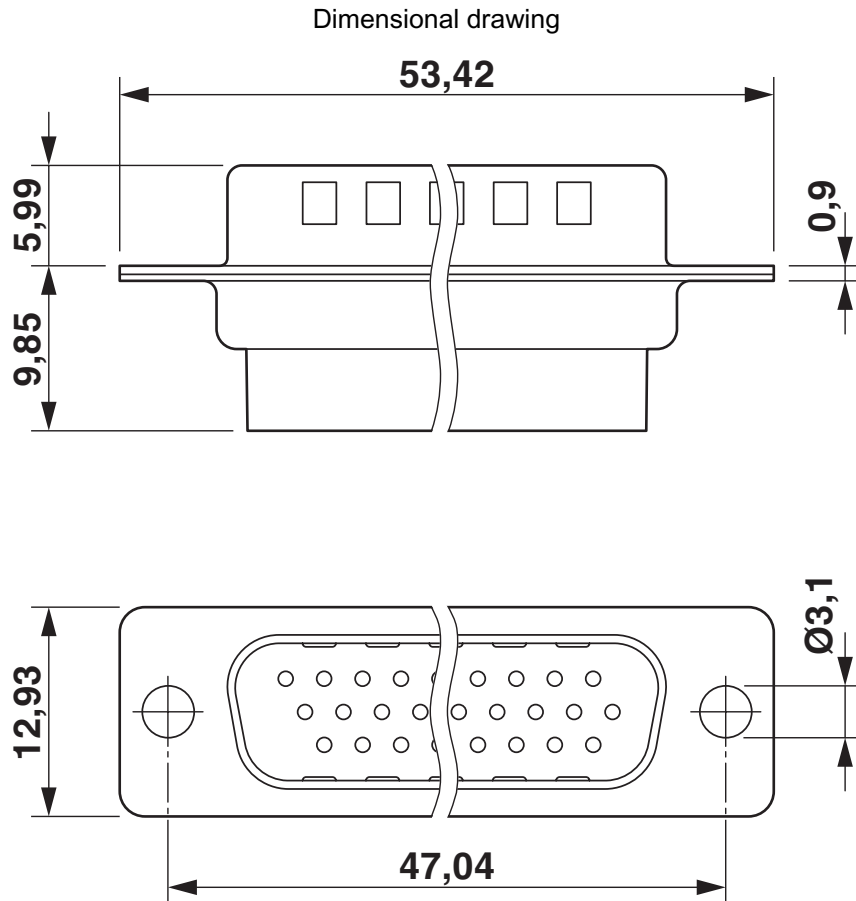

D-SUB contact carrier

VS-25-ST-DSUB-HD-CD-B - D-SUB contact support



1655250

<https://www.phoenixcontact.com/de/produkte/1655250>

Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/de/produkte/1655250>



EAC

Approval ID: B.01687

1655250

<https://www.phoenixcontact.com/de/produkte/1655250>

Classifications

ECLASS

ECLASS-11.0	27440223
ECLASS-12.0	27440223
ECLASS-13.0	27440223

ETIM

ETIM 8.0	EC003557
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

VS-25-ST-DSUB-HD-CD-B - D-SUB contact support



1655250

<https://www.phoenixcontact.com/de/produkte/1655250>

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

VS-25-ST-DSUB-HD-CD-B - D-SUB contact support



1655250

<https://www.phoenixcontact.com/de/produkte/1655250>

Accessories

CUC-DSC-C1BAU-S/DSC22 - D-SUB crimp contact

1418789

<https://www.phoenixcontact.com/de/produkte/1418789>



D-SUB crimp contact, connection method: Crimp connection, connection cross section: AWG 28- 22, High Density

CUC-DST-GPME-S/DSSC25 - D-SUB sleeve housings

1419719

<https://www.phoenixcontact.com/de/produkte/1419719>



D-SUB sleeve housings, degree of protection: IP20, material: ABS, metal-plated, cable outlet: straight, housing size: 3, color: Bare metallic

VS-25-ST-DSUB-HD-CD-B - D-SUB contact support



1655250

<https://www.phoenixcontact.com/de/produkte/1655250>

CUC-DST-GPME-A/DSSC25 - D-SUB sleeve housings

1419721

<https://www.phoenixcontact.com/de/produkte/1419721>



D-SUB sleeve housings, degree of protection: IP20, material: ABS, metal-plated, cable outlet: angled, housing size: 3, color: Bare metallic

CUC-DST-GZNI-S/DSSC25 - D-SUB sleeve housings

1419727

<https://www.phoenixcontact.com/de/produkte/1419727>



D-SUB sleeve housings, degree of protection: IP20, material: Zinc die-cast, cable outlet: straight, housing size: 3, color: Bare metallic

VS-25-ST-DSUB-HD-CD-B - D-SUB contact support



1655250

<https://www.phoenixcontact.com/de/produkte/1655250>

CUC-DST-GZNI-A/DSSC25 - D-SUB sleeve housings

1419728

<https://www.phoenixcontact.com/de/produkte/1419728>

D-SUB sleeve housings, degree of protection: IP20, material: Zinc die-cast, cable outlet: angled, housing size: 3, color: Bare metallic



VS-25-A - Panel mounting frames

1689750

<https://www.phoenixcontact.com/de/produkte/1689750>

D-SUB panel mounting frame, shell size 3, IP67 degree of protection



VS-25-ST-DSUB-HD-CD-B - D-SUB contact support

1655250

<https://www.phoenixcontact.com/de/produkte/1655250>



VS-25-T-2M20 - D-SUB sleeve housings

1689792

<https://www.phoenixcontact.com/de/produkte/1689792>

D-SUB sleeve housing, shell size 3, IP67 degree of protection



CUC-SCHRAUBE-5,5:360 - Screw

1421711

<https://www.phoenixcontact.com/de/produkte/1421711>

Screw, design: Hexagonal, color: Bare metallic



VS-25-ST-DSUB-HD-CD-B - D-SUB contact support

1655250

<https://www.phoenixcontact.com/de/produkte/1655250>



VS-25-BU-DSUB-HD-CD-B - D-SUB contact support

1655247

<https://www.phoenixcontact.com/de/produkte/1655247>

D-SUB contact carrier, shell size 3, for 44 signal contacts, type of contact socket, for crimp contacts, straight, fixing with a 3 mm hole, for panel mounting frame and sleeve housing VS-25-...



Phoenix Contact 2023 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT Deutschland GmbH

Flachsmarktstraße 8

D-32825 Blomberg

+49 52 35/3-1 20 00

info@phoenixcontact.de