


VS-08-CS-VSIP67-OE-CH-5,0

Order No.: 1656835

<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1656835>

Assembled Ethernet cable, CAT5e, shielded, 2-pair, AWG 24 solid (1-wire), RAL 5021 (water blue), RJ45/IP67 on open cable end, length: 5 m

Ethernet

Commercial data	
GTIN (EAN)	 4 017918 993948
Note	Made-to-order
sales group	D514
Pack	1 pcs.
Customs tariff	85444210

Product notes

WEEE/RoHS-compliant since:
05/10/2006



<http://www.download.phoenixcontact.com>
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

Technical data

Mechanical characteristics	
Number of positions	4
Shielded	Yes
External cable diameter	7.8 mm
Cable structure	2x2xAWG24/1; S-UTP
Length of cable	5 m
Ambient temperature (operation)	-30 °C ... 80 °C (cable, fixed installation)
	-5 °C ... 60 °C (cable, flexible installation)
	(Male connector / female connector)

Material data


Outer sheath, material	Halogen-free compound, HM 2 in acc. with VDE 0207
External sheath, color	water blue RAL 5021
Degree of protection	IP67

Electrical characteristics

Rated voltage (III/3)	60 V
Transmission characteristics (category)	CAT5 (IEC 11801:2002), CAT5e (TIA 568B:2001)


Diagrams/Drawings

Dimensioned drawing

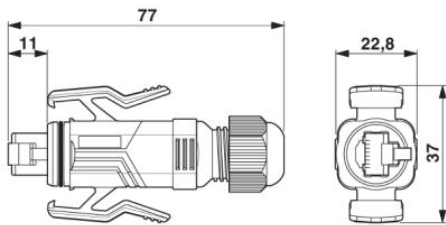


RJ45 plug connectors, IP67, QUICKON fast connection technology

Schematic diagram

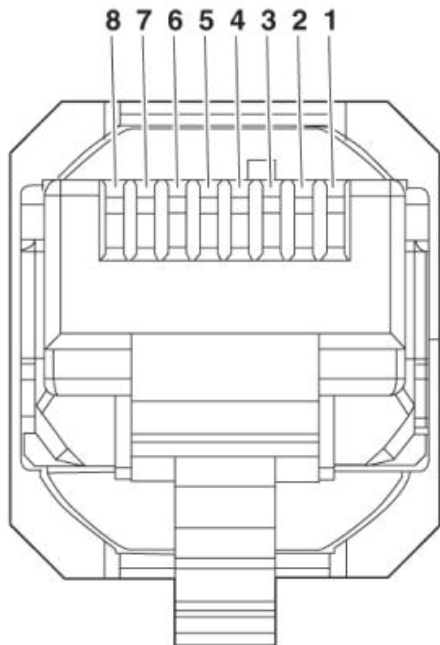

Connector pin assignment plug RJ45

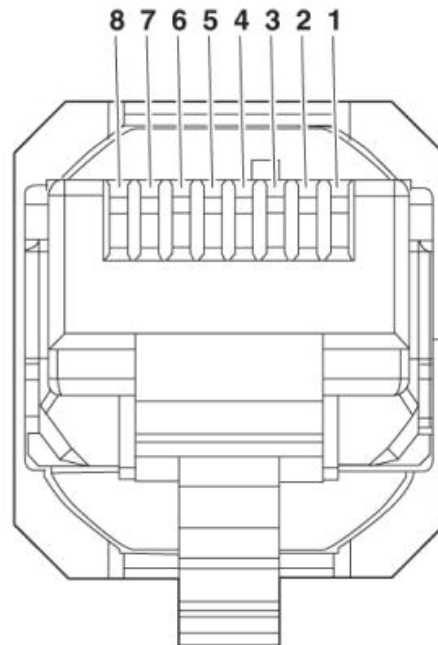

Connector pin assignment plug RJ45

Address

PHOENIX CONTACT Inc., USA
586 Fulling Mill Road
Middletown, PA 17057, USA
Phone (800) 888-7388
Fax (717) 944-1625
<http://www.phoenixcon.com>



© 2011 Phoenix Contact
Technical modifications reserved;