

Cover plate - HC-B 24-APV-GY - 1661037

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)


HEAVYCON cover plate, for wall cutouts of type B24, 7 mm thick, gray



The illustration shows a version of the product



Key commercial data

Packing unit	1 pc
GTIN	 4 017918 022433
Weight per Piece (excluding packing)	35.52 GRM
Custom tariff number	39269097
Country of origin	Germany

Technical data

Dimensions

Length	150 mm
Height	7 mm
Hole diameter	4.5 mm
Width	52 mm
Drill hole distance, horizontal	130 mm
Drill hole distance, vertical	32 mm

General

Note	For wall cutouts of type B24
Material	PA
Inflammability class according to UL 94	HB
Color	gray

Cover plate - HC-B 24-APV-GY - 1661037

Technical data

General

Design	B24
--------	-----

Classifications

eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	27440209

ETIM

ETIM 3.0	EC002309
ETIM 4.0	EC000886
ETIM 5.0	EC002314

UNSPSC

UNSPSC 6.01	30211817
UNSPSC 7.0901	39121416
UNSPSC 11	39121408
UNSPSC 12.01	39121408
UNSPSC 13.2	39121408

Approvals

Approvals

Approvals

GOST

 
Ex Approvals

Approvals submitted


Cover plate - HC-B 24-APV-GY - 1661037

Approvals

Approval details



Drawings

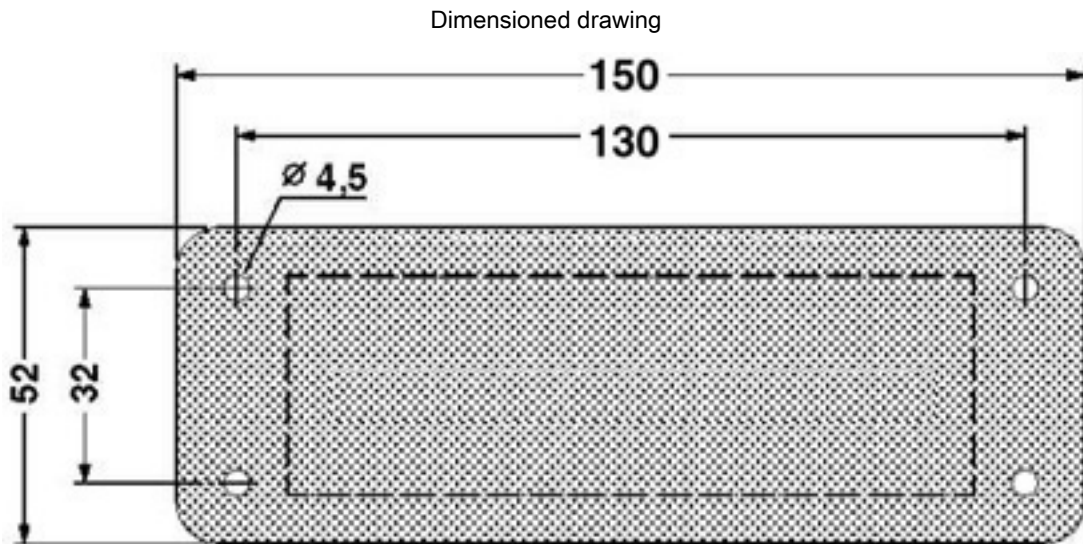

Processing area 2 mm thick