

Contact insert module - HC-M-03-MOD-BU - 1663226


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON contact insert module, female, 3-pos., crimp connection



Key Commercial Data

Packing unit	1 pc
Minimum order quantity	2 pc
GTIN	 4 017918 123031
Weight per Piece (excluding packing)	13.6 g
Custom tariff number	85369010
Country of origin	Germany

Classifications

eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	27440207

ETIM

ETIM 2.0	EC000438
ETIM 3.0	EC000438
ETIM 4.0	EC000438
ETIM 5.0	EC000438

Contact insert module - HC-M-03-MOD-BU - 1663226

Classifications

UNSPSC

UNSPSC 6.01	30211923
UNSPSC 7.0901	39121522
UNSPSC 11	39121522
UNSPSC 12.01	39121522
UNSPSC 13.2	39121522

Approvals

Approvals


Approvals


UL Recognized / CSA / EAC

Ex Approvals

Approvals submitted

Approval details

UL Recognized 	
mm ² /AWG/kcmil	8
Nominal current I _N	40 A
Nominal voltage U _N	600 V

CSA 	
mm ² /AWG/kcmil	16-10
Nominal current I _N	32 A
Nominal voltage U _N	600 V


Contact insert module - HC-M-03-MOD-BU - 1663226

Approvals

EAC


Drawings

Dimensional drawing

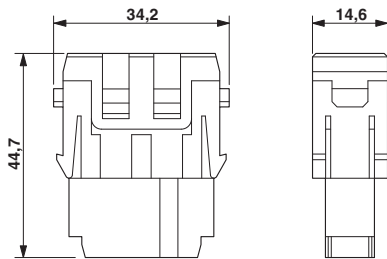

Female insert

Diagram

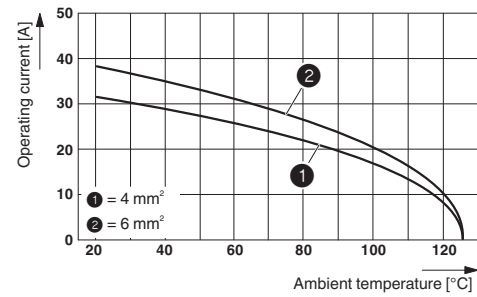

Derating diagram (6 modules in HC-B 24 housing)