

Screw plug - HC-BS-PG11 - 1674493


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Screw plug, cable gland material: Nickel-plated brass, Brass, nickel-plated, connecting thread: Pg11, color: silver

RoHS

Key Commercial Data

Packing unit	1 STK
Minimum order quantity	10 STK
GTIN	 4 017918 135393
GTIN	4017918135393
Weight per Piece (excluding packing)	8.760 g
Custom tariff number	85369010
Country of origin	Germany

Technical data

Dimensions

Length	8 mm
Hexagon angular dimension	22 mm (Diameter (no corners))
Length of the connecting thread	4.5 mm

Ambient conditions

Degree of protection	IP68
Ambient temperature (operation)	-20 °C ... 80 °C

General

Material	Brass, nickel-plated
Cable gland material	Nickel-plated brass

Screw plug - HC-BS-PG11 - 1674493

Technical data

General

O-ring material	NBR
Thread type connection side	Pg11
Color	silver

Standards and Regulations


Halogen-free	no
--------------	----

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

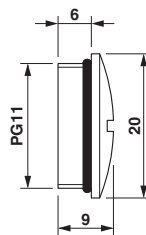

Dimensional drawing

Classifications

eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	23111190
eCl@ss 9.0	23111190

ETIM

ETIM 2.0	EC000437
ETIM 3.0	EC000437
ETIM 4.0	EC000032

Screw plug - HC-BS-PG11 - 1674493

Classifications

ETIM

ETIM 5.0	EC000723
ETIM 6.0	EC000032

UNSPSC

UNSPSC 6.01	30212113
UNSPSC 7.0901	39121712
UNSPSC 11	39121712
UNSPSC 12.01	39121712
UNSPSC 13.2	31161501

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		RU C- DE.AI30.B.01102
-----	---	--------------------------