

## Filler plugs - HC-BS-PG16 - 1674516

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Filler plugs, for Pg screw connections, type Pg16

The illustration shows version HC-BS-PG 21



### Key Commercial Data

Packing unit	1 pc
Minimum order quantity	10 pc
GTIN	 4 017918 135416
Weight per Piece (excluding packing)	18.01 g
Custom tariff number	74153300
Country of origin	Germany

### Technical data

#### Dimensions

Length	9.5 mm
Length without connecting thread	3 mm
Connecting thread diameter	23 mm
Hexagon angular dimension GRP	24 mm
Length of the connecting thread	6.5 mm

#### Ambient conditions

Degree of protection	IP68
	IP68
Ambient temperature (operation)	-20 °C ... 80 °C

#### General

# Filler plugs - HC-BS-PG16 - 1674516

## Technical data

### General

Material	Nickel-plated brass
Cable gland material	Nickel-plated brass
O-ring material	NBR
Thread type on connection side	Pg16
Color	silver
	silver

## Classifications

### eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	23111190

### ETIM

ETIM 2.0	EC000437
ETIM 3.0	EC000437
ETIM 4.0	EC000032
ETIM 5.0	EC000723

### UNSPSC

UNSPSC 6.01	30212113
UNSPSC 7.0901	39121712
UNSPSC 11	39121712
UNSPSC 12.01	39121712
UNSPSC 13.2	39121712

## Approvals

### Approvals

---

Approvals

EAC

---

## Filler plugs - HC-BS-PG16 - 1674516

### Approvals

Ex Approvals

---

Approvals submitted

---


### Approval details

EAC
-----

---

### Drawings

Dimensional drawing

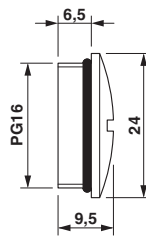

Filler plugs Pg16

---