

Screw plug - HC-BS-PG29 - 1674532


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Screw plug, material: Brass, nickel-plated, connecting thread: Pg29, color: silver



RoHS

Key Commercial Data

Packing unit	1 pc
Minimum order quantity	10 pc
GTIN	 4 017918 135430
GTIN	4017918135430
Weight per Piece (excluding packing)	43.580 g
Custom tariff number	85369010
Country of origin	Germany

Technical data

Dimensions

Length	12 mm
Hexagon angular dimension	39 mm (Diameter (no corners))
Length of the connecting thread	7 mm

Ambient conditions

Degree of protection (IP)	IP68
Ambient temperature (operation)	-20 °C ... 80 °C

General

Material	Brass, nickel-plated
O-ring material	NBR

Screw plug - HC-BS-PG29 - 1674532

Technical data

General

Thread type on connection side	Pg29
Color	silver

Standards and Regulations

Halogen-free	no
--------------	----


Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Drawings

Screw plug - HC-BS-PG29 - 1674532

Dimensional drawing

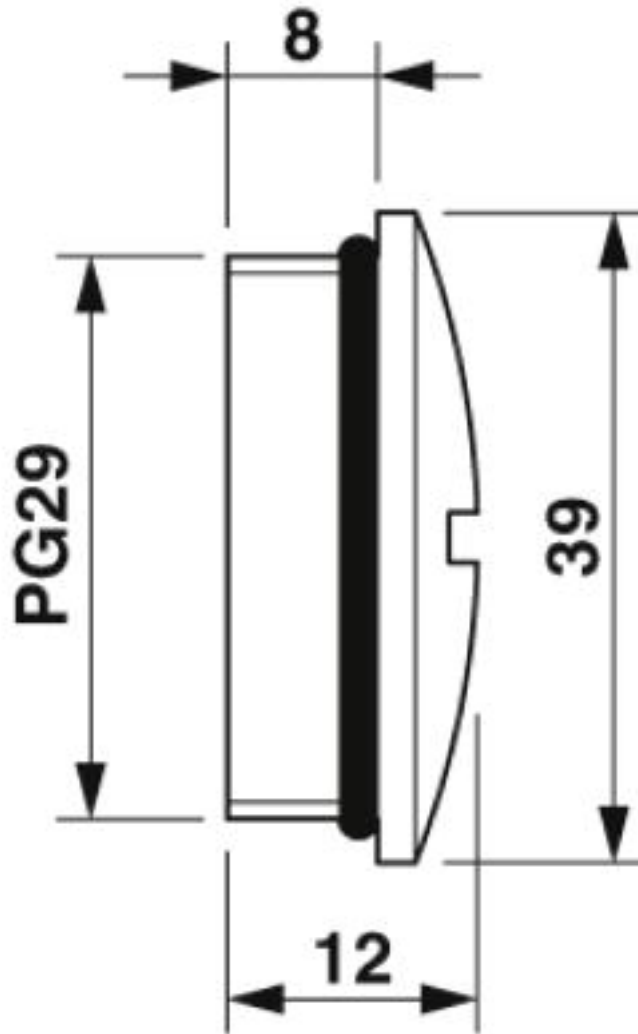

Filler plugs Pg29

Classifications

eCl@ss

eCl@ss 10.0.1	23111190
eCl@ss 4.0	23111100
eCl@ss 4.1	23111100
eCl@ss 5.0	23111100
eCl@ss 5.1	23111100

Screw plug - HC-BS-PG29 - 1674532

Classifications

eCl@ss

eCl@ss 6.0	23111100
eCl@ss 7.0	23111190
eCl@ss 8.0	23111190
eCl@ss 9.0	23111190

ETIM

ETIM 2.0	EC000437
ETIM 3.0	EC000437
ETIM 4.0	EC000032
ETIM 5.0	EC000723
ETIM 6.0	EC000032
ETIM 7.0	EC000032

UNSPSC

UNSPSC 6.01	30212113
UNSPSC 7.0901	39121712
UNSPSC 11	39121712
UNSPSC 12.01	39121712
UNSPSC 13.2	31161501

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		RU C- DE.AI30.B.01102
-----	---	--------------------------