

Pressure screw - HC-DS-PG11-T - 1686779


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Pressure screws, with flared cable bending protection, clamping area 8 mm ... 12 mm, for housings with Pg 11 support



Key Commercial Data

Packing unit	10 pc
GTIN	 4 017918 235505
GTIN	4017918235505
Sales Key	02

Technical data

Dimensions


Clamping range of the strain relief clip	8.00 mm ... 12.00 mm
--	----------------------

General

Material, pressure screw	Nickel-plated brass
Thread type on connection side	Pg11

Drawings

Dimensional drawing

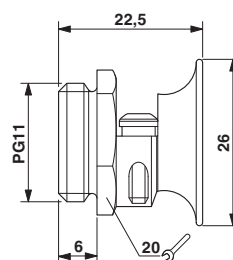

Dimensional drawing

Pressure screw - HC-DS-PG11-T - 1686779

Approvals


Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		RU C- DE.AI30.B.01102
-----	---	--------------------------

Phoenix Contact 2019 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>