

Protective covers - HC-B 16-SD-FQT/FS - 1687273

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Protective cover B16, for double locking latch, protective cover material: PA, height: 21.6 mm, seal: yes, With lanyard, diameter of retaining cord eyelet: 30 mm



Key Commercial Data

Packing unit	10 STK
GTIN	
GTIN	4017918574970

Technical data

Dimensions

Length	97 mm
Width	46 mm
Height	21.6 mm
Diameter of retaining cord eyelet	30 mm

Ambient conditions

Degree of protection	IP66
Ambient temperature (operation)	-20 °C ... 100 °C

General

Size	B16
Type	For sleeve housings with double locking latch
Material	PA
Flammability rating according to UL 94	HB
Color	gray
Seal present	yes
Connection	Plastic protective cover for short-term protection

Standards and Regulations

Protective covers - HC-B 16-SD-FQT/FS - 1687273

Technical data

Standards and Regulations


Flammability rating according to UL 94	HB
--	----

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

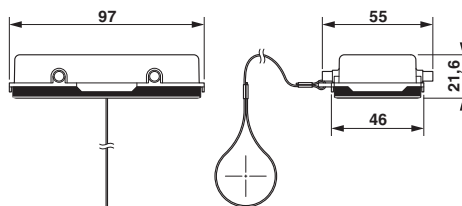

Dimensional drawing

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		RU C- DE.AI30.B.01102
-----	--	--------------------------

Phoenix Contact 2018 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>