

Protective cover - HC-B 10-TMS-SD-IP50



1690749

<https://www.phoenixcontact.com/za/products/1690749>

Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.



Protective cover B10, Clip locking, protective cover material: PA, height: 31.2 mm, seal: no, diameter of retaining cord eyelet: 4 mm, with lanyard

Protective cover - HC-B 10-TMS-SD-IP50



1690749

<https://www.phoenixcontact.com/za/products/1690749>

Commercial Data

Item number	1690749
Packing unit	10 pc
Minimum order quantity	1 pc
Sales Key	022
Product Key	BF7AZC
Catalog Page	Page 602 (C-2-2019)
GTIN	4017918890636
Weight per Piece (including packing)	34,3 g
Weight per Piece (excluding packing)	26,52 g
Customs tariff number	85389099
Country of origin	DE

Protective cover - HC-B 10-TMS-SD-IP50



1690749


<https://www.phoenixcontact.com/za/products/1690749>

Technical Data

Product properties

Type	B10
Product type	Protective cover
Type	HC-ADVANCE protective cover
Housing type	Protective cover
Seal present	no
Locking type	Clip locking

Dimensions

Dimensional drawing	
Width	55 mm
Height	31.2 mm
Length	103 mm
Diameter of retaining cord eyelet	3.5 mm

Material specifications

Color	gray
Material	PA
Flammability rating according to UL 94	V0
Material, protective cover	PA

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP50
Ambient temperature (operation)	-20 °C ... 100 °C

Protective cover - HC-B 10-TMS-SD-IP50




1690749

<https://www.phoenixcontact.com/za/products/1690749>

Drawings

Dimensional drawing

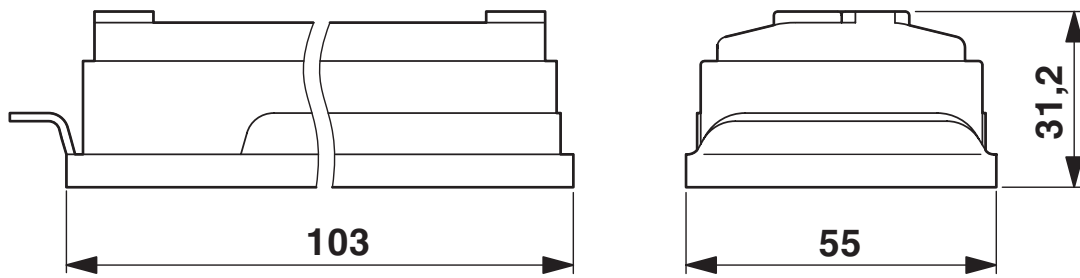

Dimensional drawing

Protective cover - HC-B 10-TMS-SD-IP50



1690749

<https://www.phoenixcontact.com/za/products/1690749>

Approvals



EAC

Approval ID: RU C-DE.AI30.B.01102

Protective cover - HC-B 10-TMS-SD-IP50



1690749

<https://www.phoenixcontact.com/za/products/1690749>

Classifications

ECLASS

ECLASS-10.0.1	27440208
ECLASS-9.0	27440208
ECLASS-11.0	27440208

ETIM

ETIM 8.0	EC002314
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

Protective cover - HC-B 10-TMS-SD-IP50



1690749

<https://www.phoenixcontact.com/za/products/1690749>

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Phoenix Contact 2022 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT (Pty) Ltd.
36 Lyn Road P.O. Box 916 ZA-Ferndale 2160

+27/11/801-8200
info@phoenixcontact.co.za