


HC-B 16-TMS-SD-IP65

Order No.: 1690794

<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1690794>

HEAVYCON ADVANCE IP65 protective cover B16, for panel mounting side, with screw locking, with retaining cord, diameter of retaining cord eyelet 3 mm

Commercial data	
GTIN (EAN)	 4 017918 890681
sales group	D291
Pack	10 pcs.
Customs tariff	39269097
Catalog page information	Page 623 (PC-2011)

Product notes

WEEE/RoHS-compliant since:
01/01/2006




<http://www.download.phoenixcontact.com>
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

Technical data	
General data	
Design	B16
Type	HC-ADVANCE protective cover
Color	gray
Locking type	Screw locking

Degree of protection	IP65
Ambient temperature (operation)	-20 °C ... 100 °C
Seal material	NBR
Material lock	High-grade steel
Material of locking screw	High-grade steel
Material, protective cover	PA
Inflammability class acc. to UL 94	V0
Assembly instructions	Tightening torque of locking screw: 3 Nm

Diagrams/Drawings

Dimensioned drawing

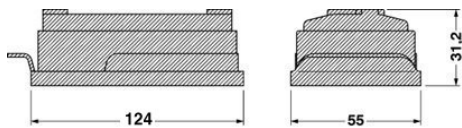

Address

PHOENIX CONTACT Inc., USA
586 Fulling Mill Road
Middletown, PA 17057, USA
Phone (800) 888-7388
Fax (717) 944-1625
<http://www.phoenixcon.com>



© 2011 Phoenix Contact
Technical modifications reserved;