


PCB terminal block - SPT 2,5/ 4-V-5,0 GYBD:2-8 EVEN - 1706411

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

PCB terminal block, Nominal current: 24 A, Nom. voltage: 400 V, Pitch: 5 mm, Number of positions: 4, Connection method: Push-in spring connection, Mounting: Wave soldering, Color: light gray

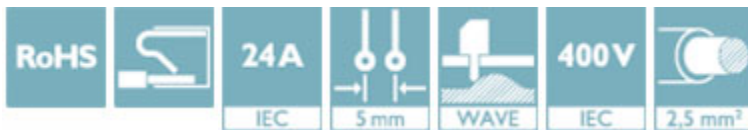

Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 272030
GTIN	4055626272030
Weight per Piece (excluding packing)	5.000 g
Custom tariff number	85369010
Country of origin	Poland

Technical data

Dimensions

Length	13.5 mm
Pitch	5 mm
Dimension a	15.00 mm
Width	11.40 mm
Constructional height	14.4 mm
Height	16.9 mm
Solder pin [P]	2.5 mm
Pin dimensions	0,8 x 0,8 mm
Pin spacing	8.20 mm
Hole diameter	1.1 mm

General

Insulating material group	I
Rated voltage (III/2)	400 V
Nominal current I_N	24 A
Nominal cross section	2.5 mm ²

PCB terminal block - SPT 2,5/ 4-V-5,0 GYBD:2-8 EVEN - 1706411

Technical data

General

Solder pin surface	Sn
Flammability rating according to UL 94	V0
Number of positions	4

Standards and Regulations

Flammability rating according to UL 94	V0
--	----

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Classifications

eCl@ss

eCl@ss 8.0	27440401
eCl@ss 9.0	27440401

ETIM

ETIM 5.0	EC002643
----------	----------