

Cable housing - KGG-PC 4/ 5-F - 1837340

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Cable housing, Pitch: 0 mm, Number of positions: 5, Dimension a: 39.9 mm, Color: green



Key Commercial Data

Packing unit	1 STK
Minimum order quantity	10 STK
GTIN	 4 017918 111359
GTIN	4017918111359
Weight per Piece (excluding packing)	20.530 g
Custom tariff number	85389099
Country of origin	Poland

Technical data

Dimensions

Pitch	0.00 mm
Dimension a	39.9 mm

General

Range of articles	KGG-PC 4/...-F
Number of positions	5
Insulating material group	0
Insulating material	ABS
Flammability rating according to UL 94	HB

Standards and Regulations

Cable housing - KGG-PC 4/ 5-F - 1837340

Technical data

Standards and Regulations


Flammability rating according to UL 94	HB
--	----

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

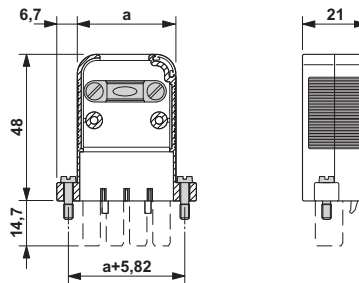

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC B.01742
