

PCB - PTF 0,3/ 4-FLEX-T-10 - 1848529

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Accessories, Number of positions: 4, Pitch: 2.4 mm, Mounting: PCB connector




Why buy this product

- T-distributor for implementing complex arrangements of flexible LED printed-circuit boards
- Easy connection of flexible LED printed-circuit boards
- Minimal heating during operation
- UL-approved materials



Key Commercial Data

Packing unit	20 STK
Minimum order quantity	20 STK
GTIN	 4 055626 282251
GTIN	4055626282251
Weight per Piece (excluding packing)	0.310 g
Custom tariff number	85340019

Technical data


Environmental Product Compliance

China RoHS	No hazardous substances above threshold values
------------	--

Drawings

PCB - PTF 0,3/ 4-FLEX-T-10 - 1848529

Dimensional drawing

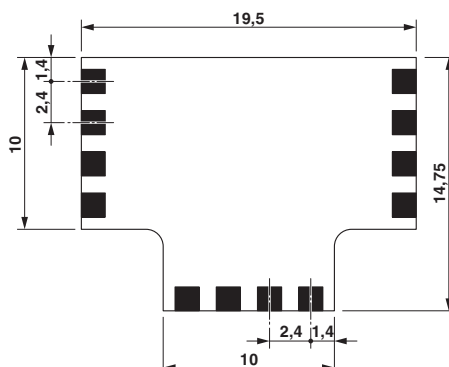

Classifications

eCl@ss

eCl@ss 5.1	27141190
eCl@ss 6.0	27260704
eCl@ss 8.0	27440402
eCl@ss 9.0	27440402

ETIM

ETIM 4.0	EC002643
ETIM 5.0	EC002637

Accessories

Additional products

Printed-circuit board connector - PTF 0,3/ 2-WB-10-H - 1707562



Plug component, Nominal current: 10 A, Rated voltage (III/2): 24 V, Number of positions: 2, Pitch: 2.4 mm, Color: white, Contact surface: Tin, Mounting: Direct plug-in method, Length of the punched-on cables: 500 mm, for flexible PCBs with a width of 10 mm and a permissible PCB thickness in the contact zone of 0.15 mm ... 0.3 mm

Printed-circuit board connector - PTF 0,3/ 4-BB-10-H - 1707563



Plug component, Nominal current: 10 A, Rated voltage (III/2): 24 V, Number of positions: 4, Pitch: 2.4 mm, Color: white, Contact surface: Tin, Mounting: Direct plug-in method, for flexible PCBs with a width of 10 mm and a permissible PCB thickness in the contact zone of 0.15 mm ... 0.3 mm

PCB - PTF 0,3/ 4-FLEX-T-10 - 1848529

Accessories

Printed-circuit board connector - PTF 0,3/ 4-WB-10-H - 1707565



Plug component, Nominal current: 10 A, Rated voltage (III/2): 24 V, Number of positions: 4, Pitch: 2.4 mm, Color: white, Contact surface: Tin, Mounting: Direct plug-in method, Length of the punched-on cables: 500 mm, for flexible PCBs with a width of 10 mm and a permissible PCB thickness in the contact zone of 0.15 mm ... 0.3 mm