

Protective covers - VC-SD-T3 - 1886744

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



VARIOCON protective cover for sleeve housing, with IP50 protection, type 3, max. tightening torque: 1.6 Nm

The figure shows the version VC-SD-T4

Why buy this product

- Easy mounting
- Contact inserts are protected when not plugged in

Key Commercial Data

Packing unit	1 STK
Minimum order quantity	5 STK
GTIN	 4 017918 908430
GTIN	4017918908430
Weight per Piece (excluding packing)	19.380 g
Custom tariff number	39269097
Country of origin	Poland

Technical data

Ambient conditions

Degree of protection	IP65
Ambient temperature (operation)	-40 °C ... 80 °C

General

Size	VC3
Type	For sleeve housing

Protective covers - VC-SD-T3 - 1886744

Technical data

General


Material	PA
Flammability rating according to UL 94	V0
Seal present	no
Assembly instructions	Tightening torque 1.6 Nm
Mounting type	Screw locking

Standards and Regulations

Flammability rating according to UL 94	V0
--	----

Drawings

Dimensional drawing

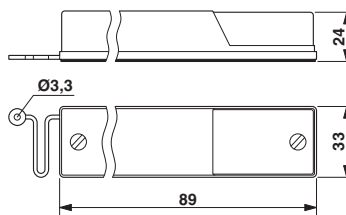

Classifications

eCl@ss

eCl@ss 4.0	27141210
eCl@ss 4.1	27141210
eCl@ss 5.0	27142104
eCl@ss 5.1	27142104
eCl@ss 6.0	27142104
eCl@ss 7.0	27142104
eCl@ss 8.0	27440208
eCl@ss 9.0	27440208

ETIM

ETIM 2.0	EC000241
ETIM 3.0	EC002040
ETIM 4.0	EC002040
ETIM 5.0	EC002314
ETIM 6.0	EC002314

Protective covers - VC-SD-T3 - 1886744

Classifications

UNSPSC

UNSPSC 6.01	30212113
UNSPSC 7.0901	39121712
UNSPSC 11	39121712
UNSPSC 12.01	39121712
UNSPSC 13.2	39121421

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		EAC-Zulassung
-----	---	---------------
