

Housing cover - ME-IO 18,8 C 9U 7035 - 2201806

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



DIN rail housing, 9U, Housing cover, width: 18.9 mm, color: light gray (7035)

Your advantages

- ✔ Item is from the ME-IO product range
- ✔ Tool-free mounting
- ✔ Available in overall widths from 18.8 mm
- ✔ Inflammability class V0 according to UL 94
- ✔ Front push-in connection technology
- ✔ Can be mounted on the DIN rail
- ✔ Optional with bus connector for DIN rail mounting

Key Commercial Data

| | |
|--------------------------------------|---------------|
| Packing unit | 1 pc |
| Minimum order quantity | 10 pc |
| GTIN | |
| GTIN | 4046356911665 |
| Weight per Piece (excluding packing) | 8.000 g |
| Custom tariff number | 85389099 |
| Country of origin | Germany |

Technical data

Item properties

| | |
|---------------------------|----------------------|
| Brief article description | Housing cover |
| Type | ME-IO 18,8 C 9U 7035 |

Housing cover - ME-IO 18,8 C 9U 7035 - 2201806

Technical data

Item properties

| | |
|----------------|------------------|
| Order No. | 2201806 |
| Housing type | DIN rail housing |
| Housing series | ME-IO |
| Type | 9U |
| Mounting type | Snap in |

Dimensions

| | |
|--------------|---------|
| Width [w] | 18.9 mm |
| Height [h] | 98.8 mm |

Material data

| | |
|--|-------------------|
| Color (RAL) | light gray (7035) |
| Flammability rating according to UL 94 | V0 |
| Housing material | Polyamide |

Ambient conditions

| | |
|---------------------------------|--|
| Ambient temperature (operation) | -40 °C ... 105 °C (depending on power dissipation) |
|---------------------------------|--|

PCB data

| | |
|-------------------|--------------------------------|
| Mounting position | Vertical (horizontal DIN rail) |
|-------------------|--------------------------------|

Packaging information

| | |
|----------------------------|------|
| Pieces per package | 10 |
| Denomination packing units | Pcs. |

Standards and regulations

| | |
|--|----|
| Flammability rating according to UL 94 | V0 |
|--|----|


Environmental Product Compliance

| | |
|------------|---|
| China RoHS | Environmentally friendly use period: unlimited = EFUP-e |
| | No hazardous substances above threshold values |

Drawings

Housing cover - ME-IO 18,8 C 9U 7035 - 2201806

Dimensional drawing

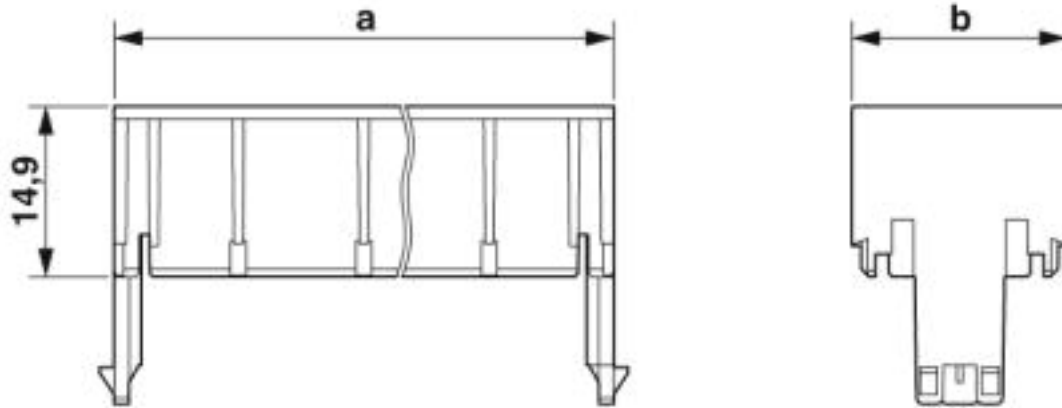

Classifications

eCl@ss

| | |
|------------|----------|
| eCl@ss 5.0 | 27180500 |
| eCl@ss 5.1 | 27180500 |
| eCl@ss 6.0 | 27180800 |
| eCl@ss 7.0 | 27182702 |
| eCl@ss 8.0 | 27182702 |
| eCl@ss 9.0 | 27182702 |

ETIM

| | |
|----------|----------|
| ETIM 4.0 | EC001031 |
| ETIM 5.0 | EC001031 |
| ETIM 6.0 | EC001031 |
| ETIM 7.0 | EC001031 |

UNSPSC

| | |
|-------------|----------|
| UNSPSC 13.2 | 31261501 |
|-------------|----------|

Approvals

Approvals

Approvals


UL Recognized / EAC


Housing cover - ME-IO 18,8 C 9U 7035 - 2201806

Approvals

Ex Approvals

Approval details

| | | | |
|---------------|---|---|---------------|
| UL Recognized |  | http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm | FILE E 240868 |
|---------------|---|---|---------------|

| | | | |
|-----|---|--|---------|
| EAC |  | | B.01742 |
|-----|---|--|---------|

Accessories

Accessories

Fiber optic

Fiber optic - HS LC-H-D2/ R4XC2-2,54 - 2202320



Light guides, passive, rigid, can be used for the ME, ME-MAX, ME-IO, ME PLC, and EH housing ranges (housing must be processed)

Fiber optic - HS LC-H-D2/ R4XC5-2,54 - 2202321



Light guides, passive, rigid, can be used for the ME, ME-MAX, ME-IO, ME PLC, and EH housing ranges (housing must be processed)

Fiber optic - HS LC-H-D2/ R4XC9-2,54 - 2202322



Light guides, passive, rigid, can be used for the ME, ME-MAX, ME-IO, ME PLC, and EH housing ranges (housing must be processed)

Housing cover - ME-IO 18,8 C 9U 7035 - 2201806

Accessories

Fiber optic - HS LC-H-D2/ R4XC10-2,54 - 2202323



Light guides, passive, rigid, can be used for the ME, ME-MAX, ME-IO, ME PLC, and EH housing ranges (housing must be processed)