

Mounting brackets - PSD-S ME BR-SM/2S - 2700161

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Angle for two-sided floor mounting, concealed cable routing, black

Your advantages

- ✓ Two-sided mounting for up to 10 signal elements
- ✓ With concealed cable routing

RoHS

Key Commercial Data

Packing unit	1 pc
GTIN	 4 046356 491518
GTIN	4046356491518
Weight per Piece (excluding packing)	75.200 g
Custom tariff number	39269097
Country of origin	Germany

Technical data

Dimensions

Diameter	70 mm
Height	98 mm

Ambient conditions

Ambient temperature (operation)	-30 °C ... 60 °C
---------------------------------	------------------

General

Material	PA A3 x 2G5
Color	black

Mounting brackets - PSD-S ME BR-SM/2S - 2700161

Technical data

General


Weight	71 g
Mounting position	any
Mounting type	Base mounting
Assembly instructions	Seal is supplied with
Scope of delivery	4 x lens sheet screw 3 x seal

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

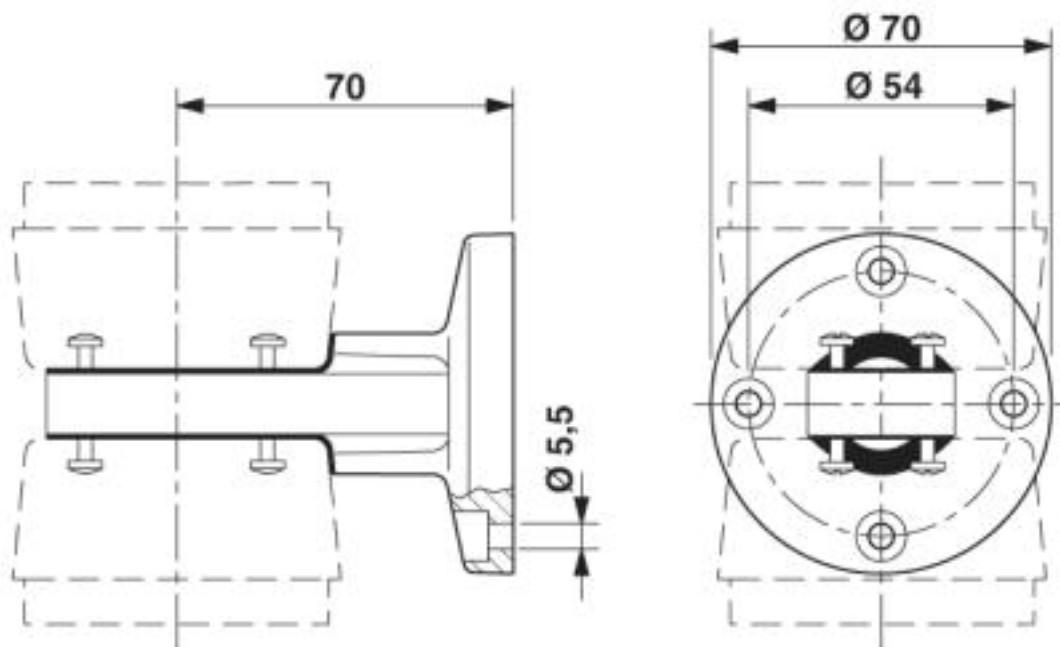

Classifications

eCl@ss

eCl@ss 4.0	27143200
eCl@ss 4.1	27143200
eCl@ss 5.0	27371200

Mounting brackets - PSD-S ME BR-SM/2S - 2700161

Classifications

eCl@ss

eCl@ss 5.1	27371200
eCl@ss 6.0	27371200
eCl@ss 7.0	27371233
eCl@ss 8.0	27371233
eCl@ss 9.0	27371233

ETIM

ETIM 3.0	EC001152
ETIM 4.0	EC001152
ETIM 5.0	EC001153
ETIM 6.0	EC001153
ETIM 7.0	EC001153

UNSPSC

UNSPSC 6.01	43172015
UNSPSC 7.0901	43201404
UNSPSC 11	39121311
UNSPSC 12.01	39121311
UNSPSC 13.2	39121311

Approvals

Approvals

Approvals

EAC / EAC

Ex Approvals

Approval details

EAC		EAC-Zulassung
-----	---	---------------

Mounting brackets - PSD-S ME BR-SM/2S - 2700161

Approvals

EAC



RU *-
DE.A*30.B.00237