

## Shield connection terminal block - SK 20-D - 3026887

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Shield connection clamp, for direct shield on conductive mounting plates, metal thickness 1 ... 2 mm

### Why buy this product

- Easy handling
- Spring-loaded, large-surface pressure plate
- Suitable for direct and busbar mounting
- Knurled screw
- Knurled screw
- Spring-loaded, large-surface pressure plate

### Key Commercial Data

Packing unit	1 STK
Minimum order quantity	10 STK
GTIN	 4 017918 820275
GTIN	4017918820275
Weight per Piece (excluding packing)	27.130 g
Custom tariff number	85369010
Country of origin	Germany

### Technical data

#### General

Number of levels	1
Number of connections	1
Cable diameter	5 mm ... 20 mm

# Shield connection terminal block - SK 20-D - 3026887

## Technical data

### General

Color	silver
Open side panel	No

### Dimensions

Length	19.5 mm
Width	24 mm
Height	73.5 mm

### Connection data


Connection method	Screw connection
Screw thread	M4
Tightening torque max	0.8 Nm

### Environmental Product Compliance


China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

## Drawings

Dimensional drawing

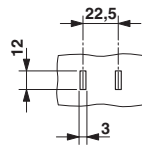


Dimensional drawing

 

Punching template

Drilling diagram

Dimensional drawing

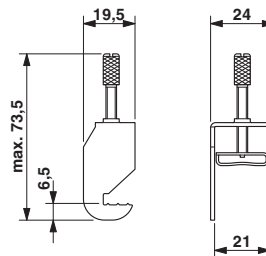

## Classifications

eCl@ss

eCl@ss 4.0	27141131
------------	----------

# Shield connection terminal block - SK 20-D - 3026887

## Classifications

### eCl@ss

eCl@ss 4.1	27141131
eCl@ss 5.0	27141131
eCl@ss 5.1	27141131
eCl@ss 6.0	27141150
eCl@ss 7.0	27141150
eCl@ss 8.0	27141150
eCl@ss 9.0	27141150

### ETIM

ETIM 2.0	EC000897
ETIM 3.0	EC000897
ETIM 4.0	EC002020
ETIM 5.0	EC002020
ETIM 6.0	EC002020

### UNSPSC

UNSPSC 6.01	30211811
UNSPSC 7.0901	39121410
UNSPSC 11	39121410
UNSPSC 12.01	39121410
UNSPSC 13.2	39121432

## Approvals

### Approvals

---

Approvals


EAC

---

Ex Approvals

---

### Approval details

EAC		7500651.22.01.00246
-----	---	---------------------

## Shield connection terminal block - SK 20-D - 3026887

### Accessories

#### Accessories

##### Installation terminal block

###### Connection terminal block - AKG 4 GNYE - 0421029



Connection terminal block, connection method: Screw connection, load current: 41 A, cross section: 0.5 mm<sup>2</sup> - 6 mm<sup>2</sup>, width: 7 mm, color: green-yellow

---

###### Connection terminal block - AKG 4 BK - 0421032



Connection terminal block, connection method: Screw connection, load current: 41 A, cross section: 0.5 mm<sup>2</sup> - 6 mm<sup>2</sup>, width: 7 mm, color: black

---

##### Pick-off terminal block

###### Connection terminal block - AK 4 - 0404017



Connection terminal block, connection method: Screw connection, load current: 41 A, cross section: 0.5 mm<sup>2</sup> - 6 mm<sup>2</sup>, width: 7 mm, color: silver

---

### Support

###### Support bracket - AB-SK - 3025341

Support bracket for busbars



## Shield connection terminal block - SK 20-D - 3026887

### Accessories

Support bracket - AB/SS - 0404428



Support bracket made from insulation material, with retaining screw, can be used with either 3 x 10 mm or 6 x 6 mm busbar, color: gray

---

---