

Cable sleeve - CES-SRG-BK-16 - 1410576

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Small, slotted cable sleeves suitable for one cable with a diameter of 15 ... 16 mm, material: NBR

Product Description

drilled special sleeve in IP44

Key Commercial Data

Packing unit	10 STK
GTIN	 4 046356 797009

Technical data

Dimensions

External cable diameter	1x 15 mm ... 16 mm
Length	29.5 mm
Width	19.5 mm
Height	17 mm

Ambient conditions

Degree of protection	IP44
Ambient temperature (operation)	-40 °C ... 125 °C (static)

General

Product description	drilled special sleeve in IP44
No. of conductors	1
Material	NBR
Color	black

Classifications

eCl@ss

eCl@ss 4.0	27081002
eCl@ss 4.1	27081002
eCl@ss 5.0	27081002

Cable sleeve - CES-SRG-BK-16 - 1410576

Classifications

eCl@ss

eCl@ss 5.1	27081002
eCl@ss 6.0	27081002
eCl@ss 7.0	27081002
eCl@ss 8.0	27069220

ETIM


ETIM 3.0	EC000879
ETIM 4.0	EC002498
ETIM 5.0	EC000451

UNSPSC

UNSPSC 6.01	30212109
UNSPSC 7.0901	39121708
UNSPSC 11	39121708
UNSPSC 12.01	39121708
UNSPSC 13.2	39121708

Drawings

Dimensional drawing

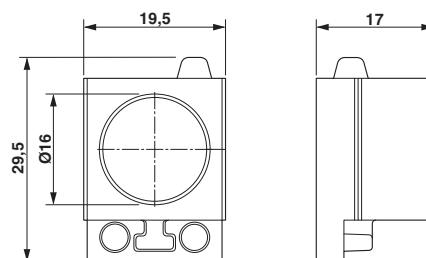

Dimensional drawing

Phoenix Contact 2016 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>