


Crimp contact - SF-08KP010 - 1621574

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Crimp contact, turned, Contact diameter: 0.8 mm, Crimp range: 0.08 mm²...0.25 mm²

Key Commercial Data

Packing unit	100 STK
Minimum order quantity	100 STK
GTIN	 4 046356 937252

Technical data

General

Insertion/withdrawal cycles mechanical	100
Contact connection method	Crimp connection
Type of contacts	Male connector
Contact diameter of power contacts	1 mm
Litz wire cross section of power contacts min.	0.06 mm²
Litz wire cross section of power contacts max.	0.25 mm²

Classifications

eCl@ss

eCl@ss 5.1	27260701
eCl@ss 6.0	27260708
eCl@ss 8.0	27440204
eCl@ss 9.0	27440204


ETIM

ETIM 4.0	EC000796
ETIM 5.0	EC000796

Drawings

Crimp contact - SF-08KP010 - 1621574

Dimensional drawing

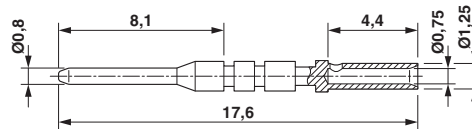

Phoenix Contact 2016 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>