


TMC 7 B3 80 57 C - Wiring bridge



1022234

<https://www.phoenixcontact.com/nl/products/1022234>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

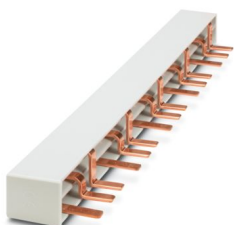

Bus bar for TMC 73... circuit breakers (three phase) 17.8 mm pitch, up to 57 positions. Rated for 80 A (end feed) 600 V AC/DC. UL 508 Listed for connection of UL 1077 rated circuit breakers.

Commercial data

Item number	1022234
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	CLA126
Product key	CLA126
GTIN	4055626516103
Weight per piece (including packing)	880 g
Weight per piece (excluding packing)	836 g
Customs tariff number	85362010
Country of origin	US

TMC 7 B3 80 57 C - Wiring bridge



1022234

<https://www.phoenixcontact.com/nl/products/1022234>

Technical data

Product properties

Type	Comb bridge
Number of positions	57

Electrical properties

Number of phases	3
Nominal voltage U_N	600 V AC/DC
Nominal current I_N	80 A (End feed)
	160 A (Center feed with two 115A TMC 8 B TERM PIN terminals required per phase)

Material specifications

Color	light gray (RAL 7035)
-------	-----------------------

TMC 7 B3 80 57 C - Wiring bridge


1022234

<https://www.phoenixcontact.com/nl/products/1022234>



Drawings

Dimensional drawing

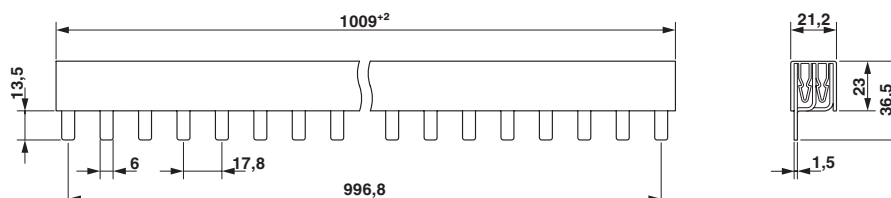

TMC 7 B3 80 57 C - Wiring bridge



1022234

<https://www.phoenixcontact.com/nl/products/1022234>

Approvals

 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/nl/products/1022234>



UL Listed

Approval ID: E123528



cUL Listed

Approval ID: E123528

TMC 7 B3 80 57 C - Wiring bridge



1022234

<https://www.phoenixcontact.com/nl/products/1022234>

Classifications

ECLASS

ECLASS-13.0	27371306
ECLASS-15.0	27371306

ETIM

ETIM 10.0	EC000215
-----------	----------

UNSPSC

UNSPSC 21.0	39121600
-------------	----------

TMC 7 B3 80 57 C - Wiring bridge



1022234

<https://www.phoenixcontact.com/nl/products/1022234>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

EF3.1 Climate Change

CO2e kg	6,158 kg CO2e
---------	---------------

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT B.V.
Hengelder 56 6902 PA Zevenaar
Postbus 246 6900 AE Zevenaar
(0316) 59 17 20
sales@phoenixcontact.nl