

HC-D50-HCWD-PLR-BK - Protective cover



1346553

<https://www.phoenixcontact.com/nl/products/1346553>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Protective cover D50, with double locking latch, protective cover material: PC, height: 29 mm, seal: yes

Commercial data

Item number	1346553
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	AF7AZC
Product key	AF7AZC
GTIN	4063151660918
Weight per piece (including packing)	59,4 g
Weight per piece (excluding packing)	59,4 g
Customs tariff number	85389099
Country of origin	CN

HC-D50-HCWD-PLR-BK - Protective cover



1346553

<https://www.phoenixcontact.com/nl/products/1346553>

Technical data

 
Notes

General	Protective cover for sleeve housings for double locking latch
---------	---

Product properties

Housing type	Protective cover
Type	D50
Retaining cord present	yes
Seal present	yes

Dimensions

Dimensional drawing	
Width	69.2 mm
Height	29 mm
Length	86.5 mm
Diameter	40 mm

Material specifications

Material Protective cover	PC
Flammability rating according to UL 94	V0
Seal material	NBR
Material, protective cover	PC

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP66
Ambient temperature (operation)	-40 °C ... 125 °C
Resistance to UV radiation	yes

Mounting

Assembly note	Double eyelet for mounting on a cable / below screw head Plastic protective cover for short-term protection
---------------	--


HC-D50-HCWD-PLR-BK - Protective cover

1346553

<https://www.phoenixcontact.com/nl/products/1346553>

Drawings

Dimensional drawing

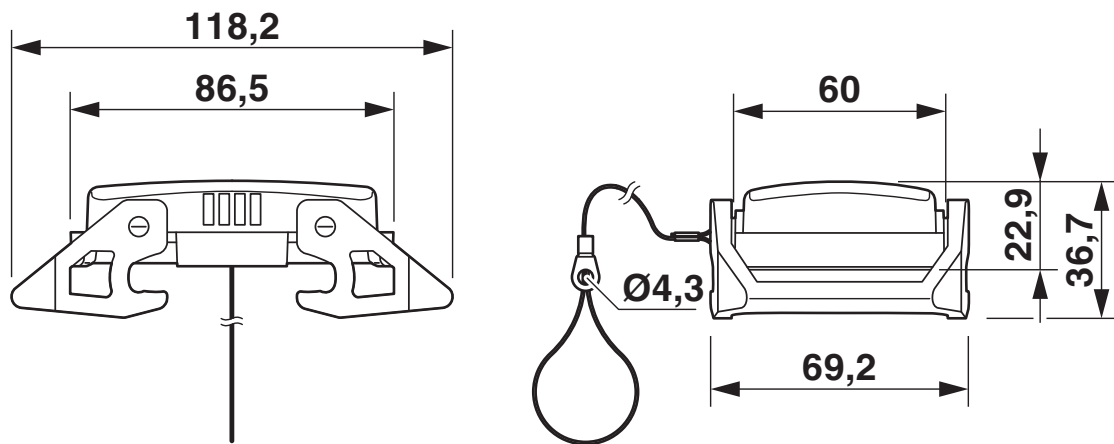

Dimensional drawing

HC-D50-HCWD-PLR-BK - Protective cover



1346553

<https://www.phoenixcontact.com/nl/products/1346553>

Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/nl/products/1346553>

DNV

Approval ID: TAE000037S

HC-D50-HCWD-PLR-BK - Protective cover



1346553

<https://www.phoenixcontact.com/nl/products/1346553>

Classifications

ECLASS

ECLASS-13.0	27440208
ECLASS-15.0	27440208

ETIM

ETIM 10.0	EC002314
-----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

HC-D50-HCWD-PLR-BK - Protective cover



1346553

<https://www.phoenixcontact.com/nl/products/1346553>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT B.V.
Hengelder 56 6902 PA Zevenaar
Postbus 246 6900 AE Zevenaar
(0316) 59 17 20
sales@phoenixcontact.nl