


Protective covers - HC-B16-HCLWD-PLR-BK - 1414639

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Protective cover B16, with double locking latch, protective cover material: PA, height: 21.6 mm, seal: yes, diameter of retaining cord eyelet: 30 mm

Key Commercial Data

Packing unit	10 pc
GTIN	 4 055626 131337
GTIN	4055626131337

Technical data

Dimensions

Length	93.5 mm
Width	43 mm
Height	21.6 mm
Diameter of retaining cord eyelet	30 mm

Ambient conditions

Degree of protection (IP)	IP66
Ambient temperature (operation)	-20 °C ... 100 °C

General

Size	B16
Material	PA
Seal material	NBR
Flammability rating according to UL 94	HB
Color	black
Seal present	yes
Note	Protective cover for supporting base element for double locking latch
Connection	Plastic protective cover for short-term protection

Protective covers - HC-B16-HCLWD-PLR-BK - 1414639

Technical data

Standards and Regulations


Flammability rating according to UL 94	HB
--	----

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

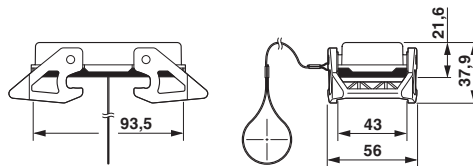

Dimensional drawing

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		RU C- DE.AI30.B.01102
-----	--	--------------------------

Phoenix Contact 2019 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>