

# HC-STA-D07-SHCWS-1SGM20-PL-BK - Housing



1419268

<https://www.phoenixcontact.com/nl/products/1419268>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Surface mounting housing D7, with single locking latch, material: PA, cable outlets: 1, straight, M20, height: 28 mm, cable gland: with, Standard, enclosed bottom

## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 1419268       |
| Packing unit                         | 1 pc          |
| Minimum order quantity               | 1 pc          |
| Sales key                            | AF7APD        |
| Product key                          | AF7APD        |
| GTIN                                 | 4055626160191 |
| Weight per piece (including packing) | 31,9 g        |
| Weight per piece (excluding packing) | 31,7 g        |
| Customs tariff number                | 85389099      |
| Country of origin                    | CN            |

# HC-STA-D07-SHCWS-1SGM20-PL-BK - Housing



1419268

<https://www.phoenixcontact.com/nl/products/1419268>

## Technical data


### Notes

|         |                                                                         |
|---------|-------------------------------------------------------------------------|
| General | for contact inserts HC-A03, A04, D07, D08, Q02, Q03, Q04, Q05, Q07, Q12 |
|---------|-------------------------------------------------------------------------|

### Product properties

|                              |                          |
|------------------------------|--------------------------|
| Housing type                 | Surface mounting housing |
| Product family               | HC-STA-D07               |
| Application                  | Standard                 |
| Type                         | D7                       |
| No. of cable outlets         | 1                        |
| Type of the screw connection | M20                      |
| Shielded                     | no                       |
| Cable outlet                 | straight                 |
| Pg screw connection          | with                     |

### Dimensions
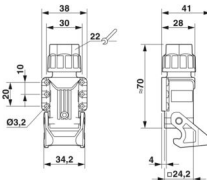
|                     |                                                                                      |
|---------------------|--------------------------------------------------------------------------------------|
| Dimensional drawing |  |
| Width               | 38 mm                                                                                |
| Height              | 28 mm                                                                                |
| Length              | 24.2 mm                                                                              |
| Hole diameter       | 3.2 mm                                                                               |

### Material specifications

|                                        |                                |
|----------------------------------------|--------------------------------|
| Flammability rating according to UL 94 | V0 (Housing)<br>V0 (Interlock) |
| Seal material                          | NBR                            |
| Housing material                       | PA                             |
| Locking latch material                 | PA                             |

### Mechanical properties

#### Mechanical data

|                              |       |
|------------------------------|-------|
| Type of the screw connection | M20   |
| Locking type                 | Latch |

### Cable/line

|                         |                |
|-------------------------|----------------|
| External cable diameter | 4 mm ... 10 mm |
|-------------------------|----------------|

# HC-STA-D07-SHCWS-1SGM20-PL-BK - Housing



1419268

<https://www.phoenixcontact.com/nl/products/1419268>

## Connection data

|                         |                |
|-------------------------|----------------|
| External cable diameter | 4 mm ... 10 mm |
| Tightening torque       | 5 Nm (Cap nut) |


## Environmental and real-life conditions

### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Degree of protection            | IP66              |
| Enclosure rating (NEMA)         | 4 (UL)            |
|                                 | 4X (UL)           |
| Impact strength                 | IK06              |
| Ambient temperature (operation) | -40 °C ... 125 °C |

## Drawings

Dimensional drawing

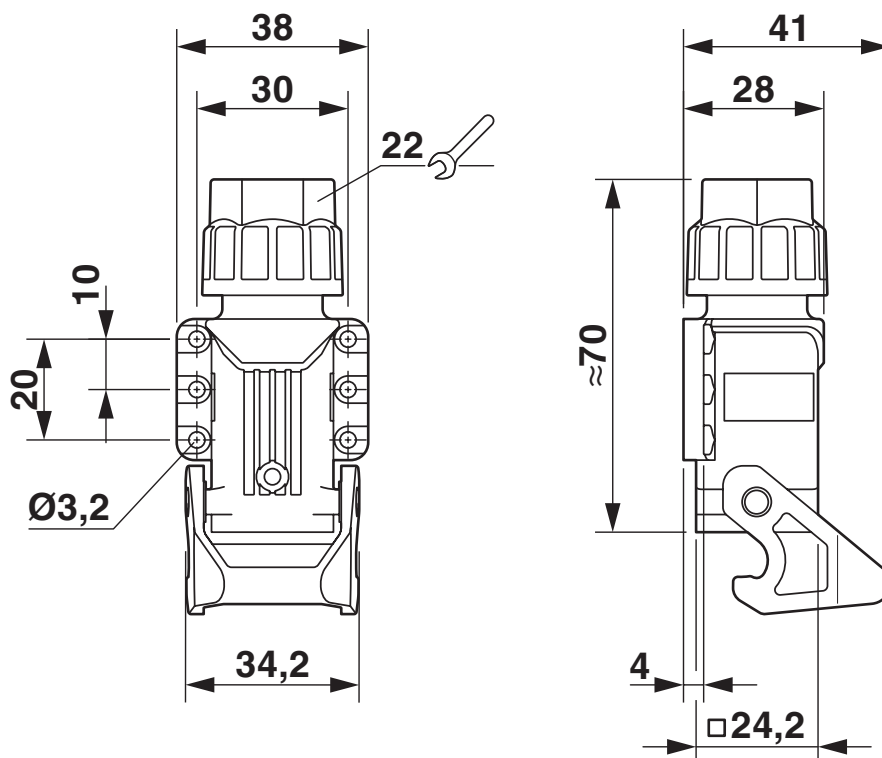

Dimensional drawing

# HC-STA-D07-SHCWS-1SGM20-PL-BK - Housing



1419268

<https://www.phoenixcontact.com/nl/products/1419268>

## Approvals

 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/nl/products/1419268>

### DNV

Approval ID: TAE000037S



### cULus Recognized

Approval ID: E468743

# HC-STA-D07-SHCWS-1SGM20-PL-BK - Housing



1419268

<https://www.phoenixcontact.com/nl/products/1419268>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27440202 |
| ECLASS-15.0 | 27440202 |

### ETIM

|           |          |
|-----------|----------|
| ETIM 10.0 | EC000437 |
|-----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

## Environmental product compliance

### EU RoHS

|                                         |                    |
|-----------------------------------------|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|-----------------------------------------|--------------------|

### China RoHS

|                                        |                                          |
|----------------------------------------|------------------------------------------|
| Environment friendly use period (EFUP) | EFUP-E                                   |
|                                        | No hazardous substances above the limits |

### EU REACH SVHC

|                                     |                            |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

PHOENIX CONTACT B.V.  
Hengelder 56 6902 PA Zevenaar  
Postbus 246 6900 AE Zevenaar  
(0316) 59 17 20  
[sales@phoenixcontact.nl](mailto:sales@phoenixcontact.nl)