


Locking element - CES-B10-SFC-M-15,6 - 1423743

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Locking element, type: B10, length: 100 mm, width: 57 mm, height: 17 mm



Key Commercial Data

Packing unit	1
GTIN	 4 0 5 5 6 2 6 3 5 3 4 4 9
GTIN	4055626353449
Custom tariff number	73269098

Technical data

Dimensions

Length	100 mm
Width	57 mm
Height	17 mm

Ambient conditions

Ambient temperature (operation)	-40 °C ... 120 °C
---------------------------------	-------------------

General

Material	Steel, galvanized
Installation instructions	suitable for article 0801655, V/C: 01 (version batch), see printing of the packaging label


Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Locking element - CES-B10-SFC-M-15,6 - 1423743

Dimensional drawing

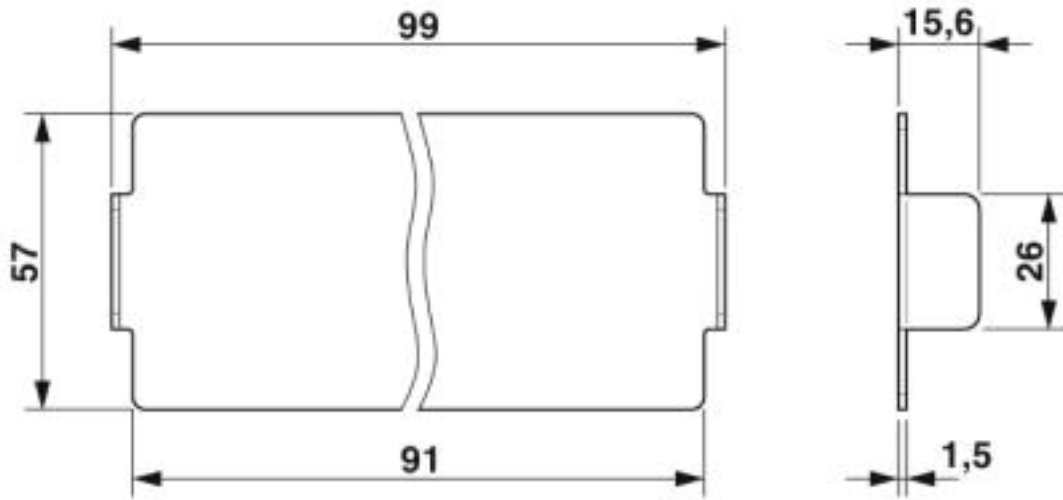

Dimensional drawing

Classifications

eCl@ss

eCl@ss 4.0	27081002
eCl@ss 4.1	27081002
eCl@ss 5.0	27081002
eCl@ss 5.1	27081002
eCl@ss 6.0	27081002
eCl@ss 7.0	27081002
eCl@ss 9.0	27440192

Approvals

Approvals

Approvals

DNV GL

Ex Approvals

Approval details

DNV GL		https://approvalfinder.dnvgl.com/	TAE00003VJ
--------	--	---	------------

