


UCS PED 7035 - Stand



2203392

<https://www.phoenixcontact.com/nl/products/2203392>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

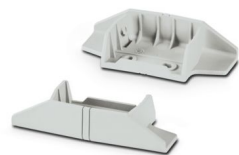

Stand for mounting the UCS housing; height: 47 mm; material: polyamide; color: light gray, similar to RAL 7035; panel mounting option is integrated, snaps into the screw holes of the housing

Your advantages

- Practical customization options
- Tool-free snap-in principle enables easy mounting on the device panel
- Flexible mounting options for the control cabinet and use in the field
- Can be adapted to suit the application, thanks to identical receptacles in the housing
- Different colors for high recognition value inside and outside the control cabinet

Commercial data

Item number	2203392
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	ACFCAZ
Product key	ACFCAZ
GTIN	4055626462509
Weight per piece (including packing)	33,4 g
Weight per piece (excluding packing)	33,4 g
Customs tariff number	39269097
Country of origin	DE

Technical data

Notes

Assembly note	Please observe the application note in the download area.
General	The UCS PED... stand has drill holes that are also suitable for panel mounting. Recommended screws for panel mounting: S5 dowel, screw $\varnothing$ 4.0 mm.

Product properties

Housing type	Universal housings
Housing series	UCS
Ventilation openings present	no

Dimensions

Width	90 mm
Height	37.5 mm
Depth	19.2 mm
Diameter mounting hole	4 mm

Material specifications

Color (Housing)	light gray (RAL 7035)
Material	PA
Flammability rating according to UL 94	V0
CTI according to IEC 60112	600
Insulating material	PA
Surface characteristics	untreated

Environmental and real-life conditions

Ambient conditions

Max. IP code to attain	IP40
Ambient temperature (operation)	-40 °C ... 105 °C (depending on power dissipation)
Ambient temperature (storage/transport)	-40 °C ... 55 °C
Ambient temperature (assembly)	-5 °C ... 100 °C
Relative humidity (storage/transport)	80 %

Mounting

Mounting type	Snap in
Mounting position	Panel mounting

Packaging specifications

Type of packaging	PE bag
-------------------	--------

UCS PED 7035 - Stand

2203392

<https://www.phoenixcontact.com/nl/products/2203392>



Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/nl/products/2203392>



UL Recognized

Approval ID: E240868

UCS PED 7035 - Stand

2203392

<https://www.phoenixcontact.com/nl/products/2203392>



Classifications

ECLASS

ECLASS-13.0	27190605
ECLASS-15.0	27190605

ETIM

ETIM 10.0	EC002779
-----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

UCS PED 7035 - Stand

2203392

<https://www.phoenixcontact.com/nl/products/2203392>



Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT B.V.
Hengelder 56 6902 PA Zevenaar
Postbus 246 6900 AE Zevenaar
(0316) 59 17 20
sales@phoenixcontact.nl