

FLT-ISG-PL-33 - Fixing plate

2905747

<https://www.phoenixcontact.com/nl/products/2905747>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Plate for fixing the FLT-ISG-100-EX isolating spark gap to a flange, drill hole diameter of 33 mm.



Commercial data

Item number	2905747
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	CL1134
Product key	CL1134
GTIN	4055626002538
Weight per piece (including packing)	172,3 g
Weight per piece (excluding packing)	172 g
Customs tariff number	73269098
Country of origin	DE

FLT-ISG-PL-33 - Fixing plate

2905747

<https://www.phoenixcontact.com/nl/products/2905747>



Technical data

Material specifications


Color	zinc color
	gray (RAL 7042)
Material	St/tZn

Mounting

Mounting type	Screw mounting
---------------	----------------

Drawings

Dimensional drawing

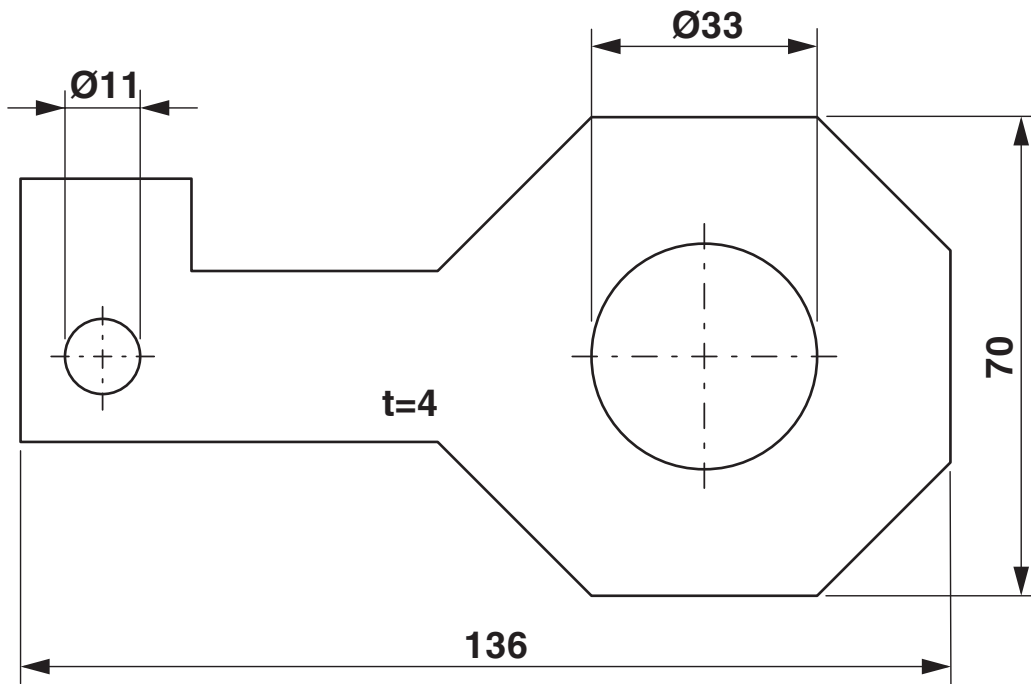

FLT-ISG-PL-33 - Fixing plate

2905747

<https://www.phoenixcontact.com/nl/products/2905747>



Classifications

ECLASS

ECLASS-13.0	27170692
ECLASS-15.0	27170692

ETIM

ETIM 10.0	EC000490
-----------	----------

UNSPSC

UNSPSC 21.0	39121700
-------------	----------

FLT-ISG-PL-33 - Fixing plate

2905747

<https://www.phoenixcontact.com/nl/products/2905747>



Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

EF3.1 Climate Change

CO2e kg	1,009 kg CO2e
---------	---------------

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT B.V.
Hengelder 56 6902 PA Zevenaar
Postbus 246 6900 AE Zevenaar
(0316) 59 17 20
sales@phoenixcontact.nl