



Extract from the online catalog

IPC 5/ 5-STGCL-7,62

Order No.: 1718290

The figure shows a 5-pos. version of the product



<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1718290>

Plug component, Nominal current: 41 A, Nom. voltage: 1000 V, Pitch: 7.62 mm, Number of positions: 5, Connection type: Screw connection, Color: green

Commercial data	
EAN	4046356175302
Pack	50 pcs.
Customs tariff	85366990
Weight/Piece	0.02267 KG
Catalog page information	Page 381 (CC-2009)

Product notes

WEEE/RoHS-compliant since: 11/23/2006



<http://www.download.phoenixcontact.com>
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

Certificates / Approvals



Certification

CUL, UL

IPC 5/ 5-STGCL-7,62 Order No.: 1718290
http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1718290

CUL


Nominal voltage U_N	600 V
Nominal current I_N	41 A
AWG/kcmil	24-8

UL


Nominal voltage U_N	600 V
Nominal current I_N	41 A
AWG/kcmil	24-8

Drawings


Diagram

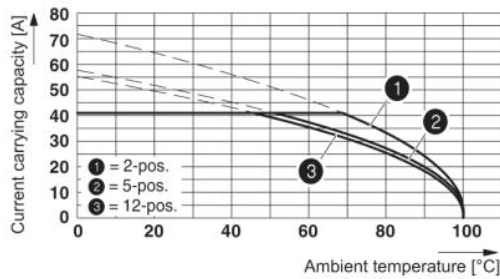

Derating curve for: IPC 5/...-ST-7.62 with PC 5/...-ST-7.62
Conductor cross section = 10 mm²

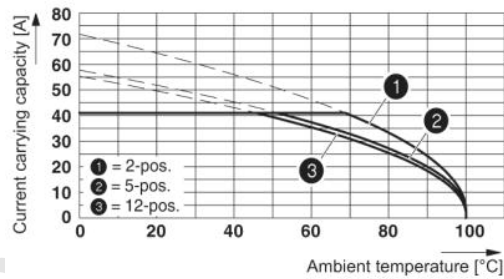


Derating curve for: IPC 5/...-ST-7.62 with IPC 5/...-G-7.62
Conductor cross section = 10 mm²

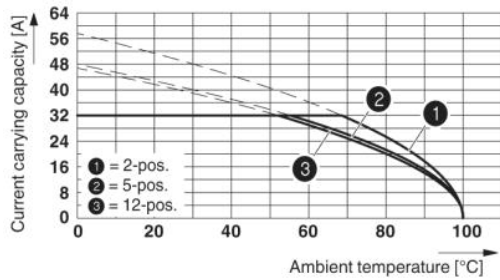

Derating curve for: IPC 5/...-ST-7,62 with IPC 5/...-G-7,62
Conductor cross section 6 mm²

Dimensioned drawing

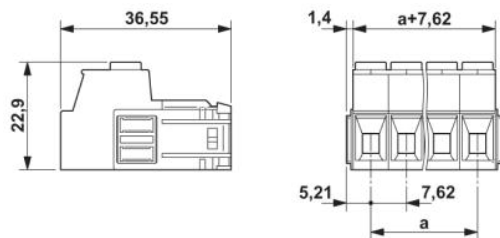

IPC 5/ 5-STGCL-7,62 Order No.: 1718290
<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1718290>

Address

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg, Germany
Phone +49 5235 3 00
Fax +49 5235 3 41200
<http://www.phoenixcontact.de>



© 2009 Phoenix Contact
Technical modifications reserved;

onlinecomponents.com