



Extract from the online catalog

PCC 4/ 7-ST-7,62

Order No.: 1840146

The illustration shows an 10-position version

<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1840146>



Plug component, Nominal current: 20 A, Nom. voltage: 400 V, Pitch: 7.62 mm, Number of positions: 7, Connection type: Crimp connection, Color: green

Commercial data	
EAN	4017918102227
Pack	50 pcs.
Customs tariff	85366990
Weight/Piece	0.00744 KG

Product notes

WEEE/RoHS-compliant since:
01/01/2003



<http://www.download.phoenixcontact.com>
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

Technical data

Dimensions / positions	
Pitch	7.62 mm
Number of positions	7

Technical data	
Insulating material group	I
Rated surge voltage (III/3)	8 kV
Rated surge voltage (III/2)	8 kV
Rated surge voltage (II/2)	8 kV
Rated voltage (III/2)	1000 V

PCC 4/ 7-ST-7,62 Order No.: 1840146
http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1840146

Rated voltage (II/2)	1000 V
Connection in acc. with standard	EN-VDE
Nominal current I _N	20 A
Nominal voltage U _N	400 V
Nominal cross section	2.5 mm ²
Maximum load current	20 A
Insulating material	PA
Inflammability class acc. to UL 94	V0

Connection data

Conductor cross section stranded min.	0.5 mm ²
Conductor cross section stranded max.	2.5 mm ²
Conductor cross section AWG/kcmil min.	20
Conductor cross section AWG/kcmil max	14

Certificates / Approvals



Certification CSA, CUL, UL

CSA

Nominal voltage U _N	300 V
Nominal current I _N	10 A
AWG/kcmil	20-14

CUL

Nominal voltage U _N	600 V
Nominal current I _N	10 A
AWG/kcmil	20-14


UL

Nominal voltage U _N	600 V
Nominal current I _N	10 A
AWG/kcmil	20-14

PCC 4/ 7-ST-7,62 Order No.: 1840146
<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1840146>

Diagrams/Drawings

Dimensioned drawing

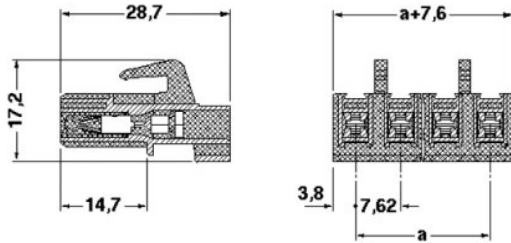

PCC 4/ 7-ST-7,62 Order No.: 1840146
<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1840146>

Address

PHOENIX CONTACT Deutschland GmbH
Flachmarktstr. 8
32825 Blomberg, Germany
Phone +49 5235 3 12000
Fax +49 5235 3 41200
<http://www.phoenixcontact.de>



© 2010 Phoenix Contact
Technical modifications reserved;

onlinecomponents.com