




Extract from the online catalog

FLKM 20/ZFKDS

Order No.: 2302913

The illustration shows a 40-position version

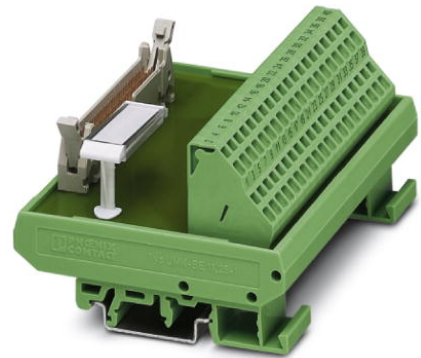

<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=2302913>

Standard 1:1 FLK module, with spring-cage connection and flat-ribbon cable plug connector, no. of positions 20

Commercial data	
EAN	4017918941437
Pack	1 pcs.
Customs tariff	85369010
Weight/Piece	0.1167 KG
Catalog page information	Page 280 (IF-2009)

Product notes

WEEE/RoHS-compliant since:
03/31/2006



<http://www.download.phoenixcontact.com>
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

Technical data

General data	
Nominal voltage U_N	< 50 V AC
	60 V DC
Max. current carrying capacity per branch	1 A
Number of positions	20
Width	57 mm

FLKM 20/ZFKDS Order No.: 2302913
http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=2302913


Height	51 mm
Depth	77 mm
Ambient temperature (operation)	-20 °C ... 50 °C
Ambient temperature (storage/transport)	-20 °C ... 70 °C
Mounting position	Any
Standards/regulations	IEC 60664
	DIN EN 50178
	IEC 62103

Connection data

Connection 1	PCB connection
Type of connection	Spring-cage connection
Conductor cross section solid min.	0.2 mm ²
Conductor cross section solid max.	4 mm ²
Conductor cross section stranded min.	0.2 mm ²
Conductor cross section stranded max.	2.5 mm ²
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	12
Connection 2	Flat-ribbon cable connection
Type of connection	Pluggable

Diagrams/Drawings

Circuit diagram

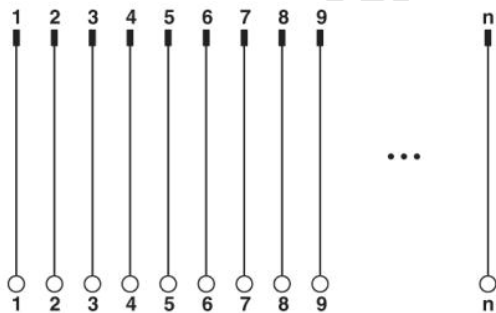

FLKM 20/ZFKDS Order No.: 2302913
<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=2302913>

Address

PHOENIX CONTACT Deutschland GmbH
Flachmarktstr. 8
32825 Blomberg, Germany
Phone +49 5235 3 12000
Fax +49 5235 3 41200
<http://www.phoenixcontact.de>



© 2010 Phoenix Contact
Technical modifications reserved;

onlinecomponents.com