




Extract from the online
catalog

FLKM-D25 SUB/S/ZFKDS

Order No.: 2303006

The illustration shows the version FLKM-D37 SUB/S/ZFKDS

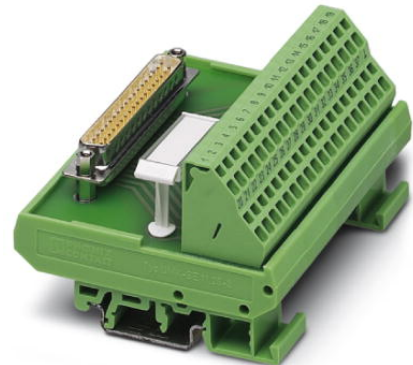

<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=2303006>

Standard 1:1 D-SUB module, with spring-cage connection and D-SUB
pin strip, no. of positions 25

Commercial data

GTIN (EAN)	4017918943974
sales group	I011
Pack	1 pcs.
Customs tariff	85369010
Weight/Piece	0.147 KG
Catalog page information	Page 286 (IF-2009)

Product notes

WEEE/RoHS-compliant since:
08/06/2008



[http://
www.download.phoenixcontact.com](http://www.download.phoenixcontact.com)
Please note that the data given
here has been taken from the
online catalog. For comprehensive
information and data, please refer
to the user documentation. The
General Terms and Conditions of
Use apply to Internet downloads.

Technical data

General data

Nominal voltage U_N	125 V AC/DC
Max. current carrying capacity per branch	2.5 A
	1.5 A (with even load on all branches)
Number of positions	25

FLKM-D25 SUB/S/ZFKDS Order No.: 2303006
http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=2303006

Width	78.8 mm
Height	52 mm
Depth	77 mm
Ambient temperature (operation)	-20 °C ... 50 °C
Ambient temperature (storage/transport)	-20 °C ... 70 °C
Mounting position	Any
Standards/regulations	IEC 60664
	DIN EN 50178
	IEC 62103
Pollution degree	2
Surge voltage category	II

Connection data

Connection 1	PCB connection
Type of connection	Spring-cage connection
Conductor cross section solid min.	0.2 mm ²
Conductor cross section solid max.	4 mm ²
Conductor cross section stranded min.	0.2 mm ²
Conductor cross section stranded max.	2.5 mm ²
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	12
Connection 2	D-SUB connection

Certificates / Approvals




Certification

CUL, UL

FLKM-D25 SUB/S/ZFKDS Order No.: 2303006
<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=2303006>

Diagrams/Drawings

Circuit diagram

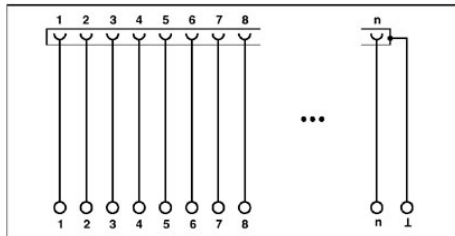

FLKM-D25 SUB/S/ZFKDS Order No.: 2303006
<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=2303006>

Address

PHOENIX CONTACT Deutschland GmbH
Flachsmarktstr. 8
32825 Blomberg, Germany
Phone +49 5235 3 12000
Fax +49 5235 3 41200
<http://www.phoenixcontact.de>



© 2010 Phoenix Contact
Technical modifications reserved;

onlinecomponents.com