




Extract from the online catalog

FLKM-D15 SUB/B/ZFKDS

Order No.: 2304047

The illustration shows the version FLKM-D37 SUB/S/ZFKDS

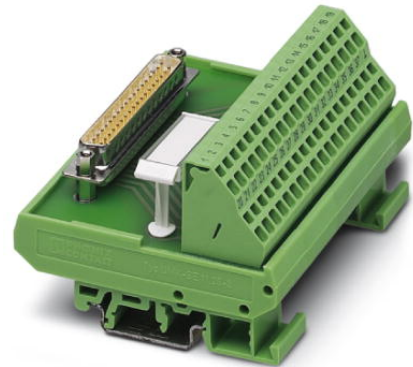

<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=2304047>

Standard 1:1 D-SUB module, with spring-cage connection and D-SUB socket strip, no. of positions 15

Commercial data	
EAN	4017918944018
Pack	1 pcs.
Customs tariff	85369010
Weight/Piece	0.1022 KG
Catalog page information	Page 286 (IF-2009)

Product notes

WEEE/RoHS-compliant since:
05/10/2006



<http://www.download.phoenixcontact.com>
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

Technical data

General data	
Nominal voltage U_N	125 V AC/DC
Max. current carrying capacity per branch	2.5 A
	1.5 A (with even load on all branches)
Number of positions	15

FLKM-D15 SUB/B/ZFKDS Order No.: 2304047
http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=2304047

Width	45 mm
Height	52 mm
Depth	77 mm
Status display	No
Ambient temperature (operation)	-20 °C ... 50 °C
Ambient temperature (storage/transport)	-20 °C ... 70 °C
Test voltage	800 V (50 Hz, 1 min.)
Mounting position	Any
Assembly instructions	In rows with zero spacing
Standards/regulations	IEC 60664
	DIN EN 50178
	IEC 62103
Pollution degree	2
Surge voltage category	II

Connection data

Connection 1	PCB connection
Type of connection	Spring-cage connection
Number of positions	16
Conductor cross section solid min.	0.2 mm ²
Conductor cross section solid max.	4 mm ²
Conductor cross section stranded min.	0.2 mm ²
Conductor cross section stranded max.	2.5 mm ²
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	12
Stripping length	7 mm
Connection 2	D-SUB connection
Type of connection	Pluggable
Number of positions	15

Certificates / Approvals




Certification CUL, UL

FLKM-D15 SUB/B/ZFKDS Order No.: 2304047
<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=2304047>

Diagrams/Drawings

Circuit diagram

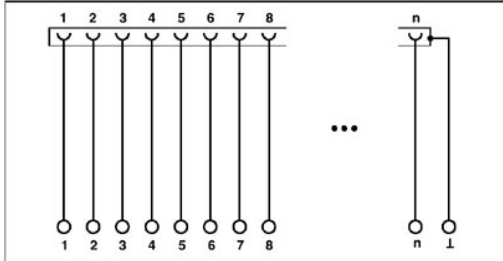

onlinecomponents.com

FLKM-D15 SUB/B/ZFKDS Order No.: 2304047
<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=2304047>

Address

PHOENIX CONTACT Deutschland GmbH
Flachmarktstr. 8
32825 Blomberg, Germany
Phone +49 5235 3 12000
Fax +49 5235 3 41200
<http://www.phoenixcontact.de>



© 2010 Phoenix Contact
Technical modifications reserved;

onlinecomponents.com